



All AMP-LATCH UNIVERSAL HEADERS (523)

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Wave solder capable to 265°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Customers Also Bought



TE Part #2-1761606-9
IDC LOW PRO HDR 26P VERT LA



TE Part #CAT-AM74-UN384H
AMP-LATCH UNIVERSAL HEADERS



TE Part #5227726-2
ISOLATED BNC SOLDER JACK ASSY



TE Part #4-644456-0
10P MTA100 HDR ASSY (NARROW)




TE Part #5747840-4
HD-20 PLUG RA .318 FMS BD-LK 4



TE Part #3-640601-4
04P MTA156 CONN ASSY 22AWG LF



TE Part #5227222-3
VERT JK W/MTG PINS, BNC PCB

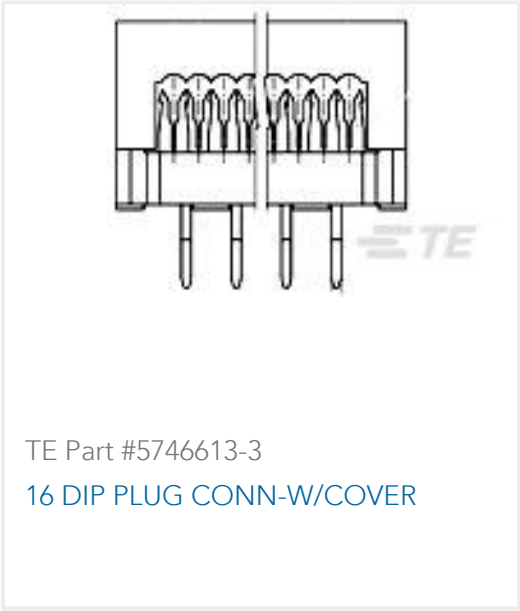

TE Part #5746613-3
16 DIP PLUG CONN-W/COVER



TE Part #1546670-6
6P .437" DR BARRIER,W/BND SCRWW

Documents

Product Drawings

A/L UNIV HDR 24P RA

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_5102159-5_A.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_5102159-5_A.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_5102159-5_A.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications



Product Specification

English

Agency Approvals

Agency Approval Document

English