



Tool Storage & Tool Modules



TOOL KITS IN ROLLER CABINETS

Tool System Solutions from RS for Garages, Factories and Workshops

RS PLUS

Our revised program consists of various combinations of tools for users in different industries, presented in roller cabinets with the highest build quality. All the tools in the system are offered in double colour EVA modules, each tool has its unique 3D cutout slot for a comfortable and snug fit. This system helps inventory control by the detection of missing tools at a glance, contributing to your overall economy and efficiency. All the mechanical hand tools in the system are guaranteed against defects in material and production.



RS Tool Modules

Increased efficiency in workshops, missing tools can be identified at a glance thanks to the two colour design.

3 dimensional cut outs for each tool for a comfortable, snug fit

Finger spaces for easy removal of tools

Chemically resistant high quality EVA material







TOOL CABINETS & TOOL CHESTS

8335900 7 Drawer RS PLUS

- Sturdy and dependable construction, premium quality sheet steel.
- Elegant and durable electrostatic matt powder coated, scratch proof.
- 7 fully extendible drawers – compatible with tool modules inlays
- Each drawer can accommodate 3 EVA tool modules
- Smart-Lock™ system on every drawer preventing accidental opening while the cabinet is on the move.
- Low friction telescopic ball bearing slides ensuring silk smooth operation.
- Central locking mechanism.
- Heavy duty oil proof rubber wheels, two fixed and two swivelling, one with an emergency brake.
- Holders for spray cans and paper rolls.
- Recessed worktop with a high quality mat to ensure a convenient working area.



RS PLUS

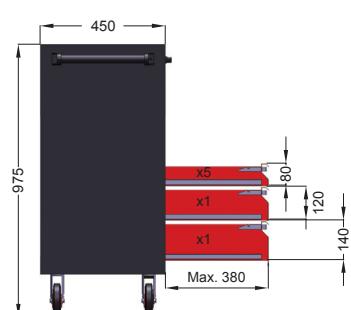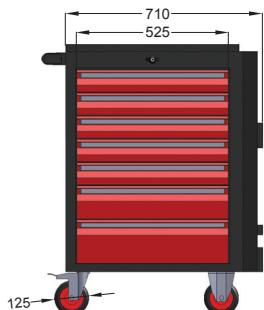



| CODE NO | HxWxD / mm | kg |
|---------|-----------------|------|
| 8335900 | 975 x 710 x 450 | 66.4 |

8335903 7 Drawer RS PLUS Jumbo

- Sturdy and dependable construction, premium quality sheet steel.
- Elegant and durable electrostatic matt powder coated, scratch proof.
- 7 fully extendible drawers – compatible with tool modules inlays
- Each drawer can accommodate 4 EVA tool modules
- Smart-Lock™ system on every drawer preventing accidental opening while the cabinet is on the move.
- Low friction telescopic ball bearing slides ensuring silk smooth operation.
- Central locking mechanism.
- Holders for spray cans and paper rolls.
- Recessed worktop with a high quality mat to ensure a convenient working area.



RS PLUS

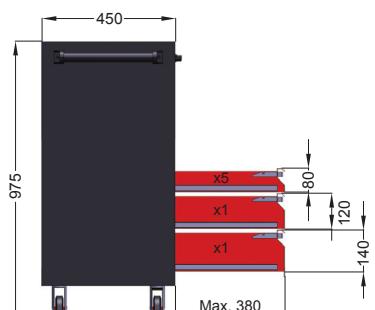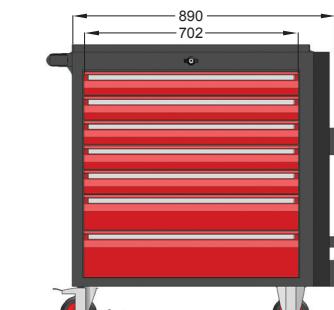

| CODE NO | HxWxD / mm | kg |
|---------|-----------------|------|
| 8335903 | 975 x 890 x 450 | 72.5 |

7 drawers
XL Dimensions




TOOL CABINETS & TOOL CHESTS

8335907

4 Drawer Chest Jumbo

- Sturdy and dependable construction, premium quality sheet steel.
- Elegant and durable electrostatic matt powder coated, scratch proof.
- 4 drawers - compatible with tool modules inlays.
- Each drawer can accommodate 4 EVA tool modules.
- 80 mm deep top locker with integrated locking mechanism
- Low friction telescopic ball bearing slides ensuring silk smooth operation.
- Integrated carrying handles.

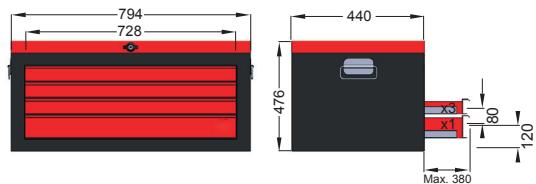

RS PLUS



4 drawers

| CODE NO | HxWxD / mm | kg |
|---------|-----------------|----|
| 8335907 | 476 x 794 x 440 | 20 |

8335916

11 Drawer Cabinet


- Sturdy and dependable construction, premium quality sheet steel.
- Elegant and durable electrostatic matt powder coated, scratch proof.
- 11 fully extendible drawers – 5 of which are compatible with tool modules inlays.
- Each drawer on the left can accommodate 3 EVA tool modules.
- Low friction telescopic ball bearing slides ensuring silk smooth operation.
- Bottom drawer with double slides.
- Foamed rubber mats in drawer bases.
- Central locking mechanism. No possibility of key match.
- Smart-Lock™ system on every drawer preventing accidental opening while the cabinet is on the move.
- Recessed worktop with a high quality mat to ensure a convenient working area.



RS PLUS



11 drawers

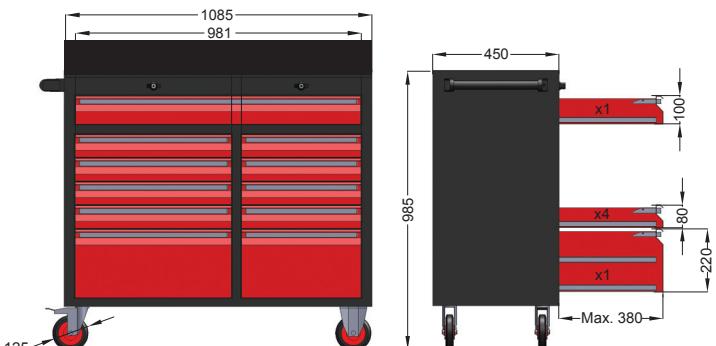

| CODE NO | HxWxD / mm | kg |
|---------|------------------|----|
| 8335916 | 985 x 1085 x 450 | 90 |



TOOL CABINETS & TOOL CHESTS

- Heavy Duty Tool Cabinets
- Standard Duty Tool Cabinets
- Maintenance Cart
- Mobile Tool Cupboard
- Service Cart




7531573

3 Drawer Heavy Duty Tool Cabinet

- Sturdy and dependable construction, premium quality sheet steel.
- Elegant and durable electrostatic matt powder coated, scratch proof.
- 3 fully extendible drawers
- Each drawer can accommodate 3 EVA tool modules.
- Low friction telescopic ball bearing slides ensuring silk smooth operation.
- Central locking mechanism.
- 100 diameter, 2 locking swivel castors and 2 fixed castors



Heavy Duty

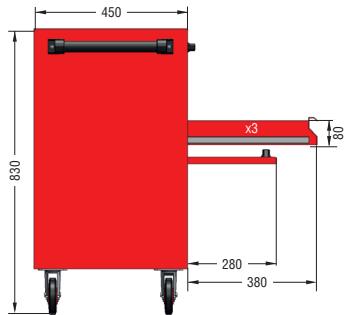


7531573

5 Drawer Heavy Duty Tool Cabinet

- Sturdy and dependable construction, premium quality sheet steel.
- Elegant and durable electrostatic matt powder coated, scratch proof.
- 5 fully extendible drawers
- Each drawer can accommodate 3 EVA tool modules.
- Low friction telescopic ball bearing slides ensuring silk smooth operation.
- Central locking mechanism.
- 100 diameter, 2 locking swivel castors and 2 fixed castors



Heavy Duty

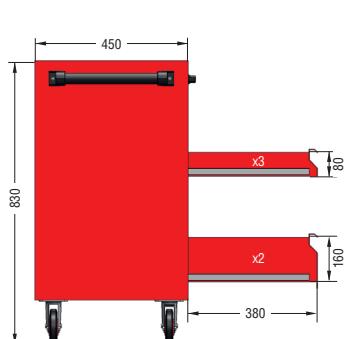

7531576

HxWxD / mm

kg

| CODE NO | HxWxD / mm | kg |
|---------|-----------------|-------|
| 7531573 | 830 x 630 x 450 | 39.30 |


TOOL CABINETS & TOOL CHESTS

7531570

6 Drawer Heavy Duty Tool Cabinet

- Sturdy and dependable construction, premium quality sheet steel.
- Elegant and durable electrostatic matt powder coated, scratch proof.
- 6 fully extendible drawers
- Each drawer can accommodate 3 EVA tool modules.
- Low friction telescopic ball bearing slides ensuring silk smooth operation.
- Central locking mechanism.
- 100 diameter, 2 locking swivel castors and 2 fixed castors

Heavy Duty

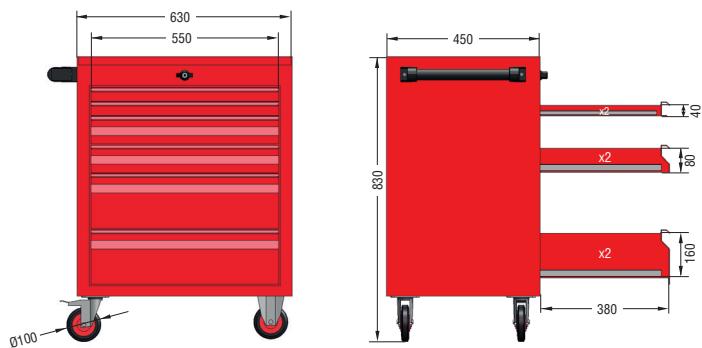

TOOL • PICK & MIX •
MODULES PER DRAWER
3


6 drawers

7531589

7 Drawer Heavy Duty Tool Cabinet

- Sturdy and dependable construction, premium quality sheet steel.
- Elegant and durable electrostatic matt powder coated, scratch proof.
- 7 fully extendible drawers
- Each drawer can accommodate 3 EVA tool modules.
- Low friction telescopic ball bearing slides ensuring silk smooth operation.
- Central locking mechanism.
- 100 diameter, 2 locking swivel castors and 2 fixed castors

Heavy Duty

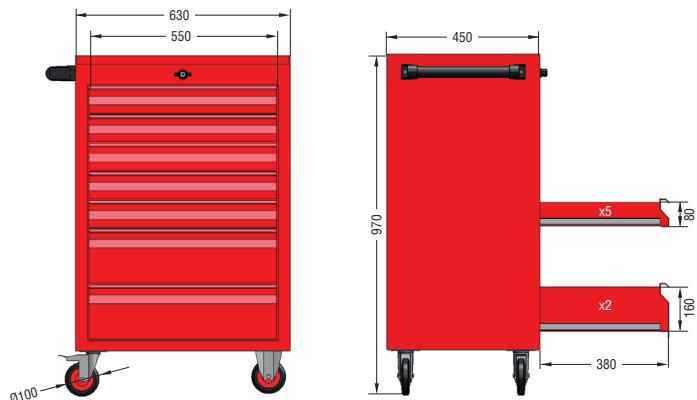

TOOL • PICK & MIX •
MODULES PER DRAWER
3

7 drawers

| CODE NO | HxWxD / mm | kg |
|---------|-----------------|-------|
| 7531589 | 970 x 630 x 450 | 58.90 |

TOOL CABINETS & TOOL CHESTS

7531582


12 Drawer Maintenance Cart

- Sturdy and dependable construction, premium quality sheet steel.
- Elegant and durable electrostatic matt powder coated, scratch proof.
- 12 fully extendible drawers
- Each drawer on the left can accommodate 3 EVA tool modules.
- Low friction telescopic ball bearing slides ensuring silk smooth operation.
- Central locking mechanism.
- 125 diameter, 2 locking swivel castors and 2 fixed castors



12 drawers

Heavy Duty

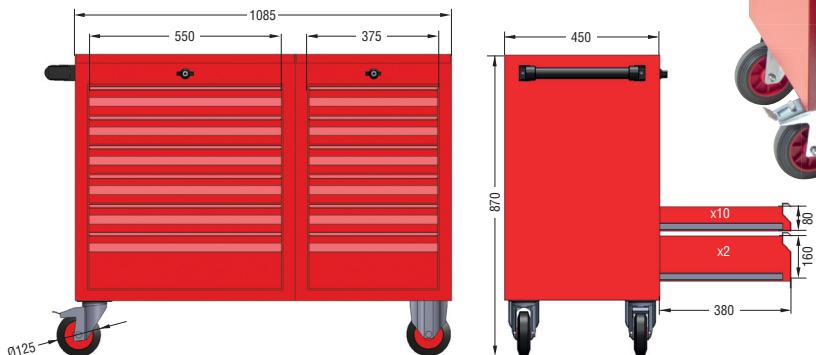


| CODE NO | HxWxD / mm | kg |
|---------|--------------|-------|
| 7531582 | 870x1085x450 | 87.75 |

7531592

Service Cart

- Sturdy and dependable construction, premium quality sheet steel.
- Elegant and durable electrostatic matt powder coated, scratch proof.
- Base, middle and bottom shelves with edges to contain tools.
- 125 diameter, 2 locking swivel castors and 2 fixed castors

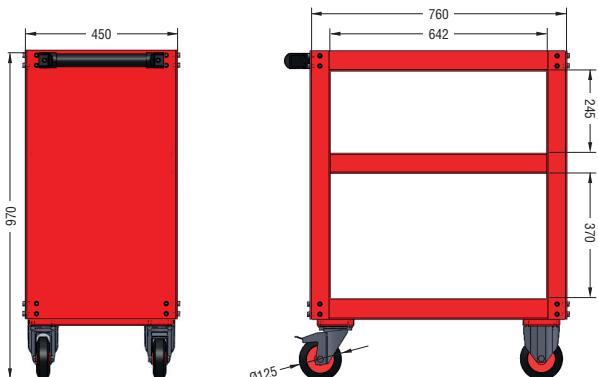

| CODE NO | HxWxD / mm | kg |
|---------|-----------------|-------|
| 7531592 | 970 x 760 x 450 | 31.60 |


7531586

5 Drawer Standard Duty Tool Cabinet

- Sturdy and dependable construction, premium quality sheet steel.
- Elegant and durable electrostatic matt powder coated, scratch proof.
- 5 fully extendible drawers
- Low friction telescopic ball bearing slides ensuring silk smooth operation.
- Padlock locking mechanism.
- 75 diameter, 2 locking swivel castors and 2 fixed castors



Standard Duty

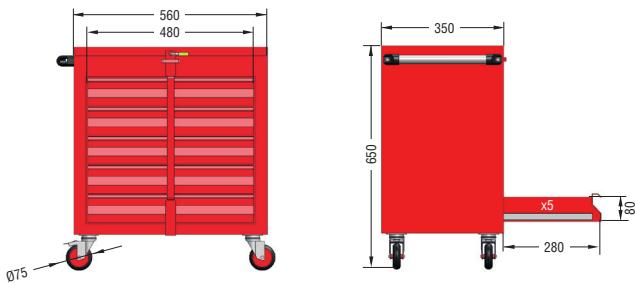

5 drawers


7531595

6 Drawer Standard Duty Tool Cabinet

- Sturdy and dependable construction, premium quality sheet steel.
- Elegant and durable electrostatic matt powder coated, scratch proof.
- 6 fully extendible drawers
- Low friction telescopic ball bearing slides ensuring silk smooth operation.
- Padlock locking mechanism.
- 75 diameter, 2 locking swivel castors and 2 fixed castors



Standard Duty

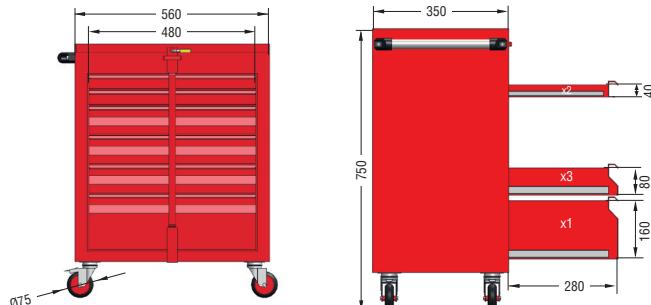

6 drawers

CODE NO

HxWxD / mm

kg

7531586

650 x 560 x 350

28.65

CODE NO

HxWxD / mm

kg

7531595


750 x 560 x 350

33.45

7531598

Mobile Tool Cupboard

- Sturdy and dependable construction, premium quality sheet steel.
- Elegant and durable electrostatic matt powder coated, scratch proof.
- Locking mechanism.
- 75 diameter, 2 locking swivel castors and 2 fixed castors

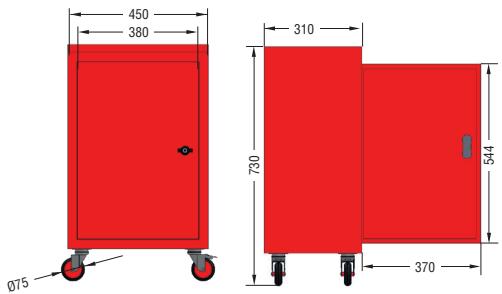


| CODE NO | HxWxD / mm | kg |
|---------|-----------------|-------|
| 7531598 | 730 x 450 x 310 | 11.95 |

7531595

6 Drawer Standard Duty Tool Cabinet

- Sturdy and dependable construction, premium quality sheet steel.
- Elegant and durable electrostatic matt powder coated, scratch proof.
- 6 fully extendible drawers
- Low friction telescopic ball bearing slides ensuring silk smooth operation.
- Padlock locking mechanism.
- 75 diameter, 2 locking swivel castors and 2 fixed castors

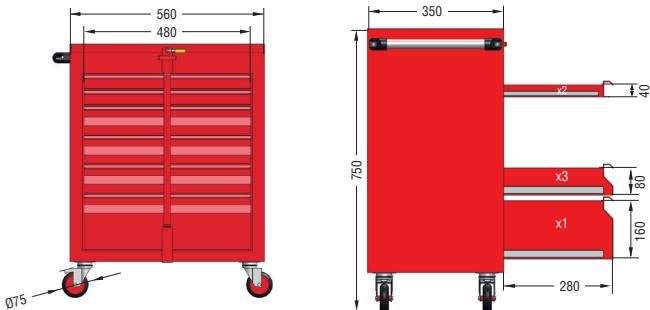


6 drawers

| CODE NO | HxWxD / mm | kg |
|---------|-----------------|-------|
| 7531595 | 750 x 560 x 350 | 33.45 |

7681678

3 Drawer Tool Chest

- Sturdy and dependable construction, premium quality sheet steel.
- Elegant and durable electrostatic matt powder coated, scratch proof.
- Easily fits onto RS PLUS and RS series roller cabinets. Especially recommended to increase the stocking capacity of these roller cabinets.
- 3 drawers - compatible with tool modules inlays.
- Each drawer can accommodate 3 EVA tool modules.
- 80 mm deep top locker with integrated locking mechanism
- Low friction telescopic ball bearing slides ensuring silk smooth operation.
- Integrated carrying handles.

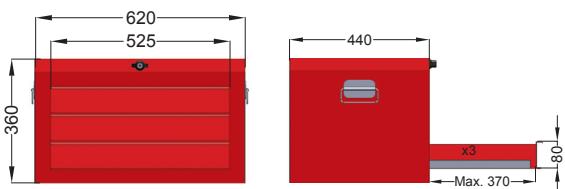


| CODE NO | HxWxD / mm | kg |
|---------|-----------------|----|
| 7681678 | 360 x 620 x 440 | 20 |

3 drawers

7681671

6 Drawer Tool Chest

- Sturdy and dependable construction, premium quality sheet steel.
- Elegant and durable electrostatic matt powder coated, scratch proof.
- 3 small drawers on the top row.
- 80 mm deep top locker.
- Low friction telescopic ball bearing slides ensuring silk smooth operation.
- Integrated carrying handles.

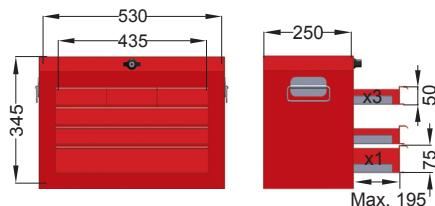

| CODE NO | HxWxD / mm | kg |
|---------|-----------------|----|
| 7681671 | 345 x 530 x 250 | 18 |

6 drawers

8335988

19" Plastic Tool Box

- Compact dimensions with highest possible storage capacity.
- Two organizers on top with lids.
- Telescoping design carry handle.
- Removable tote tray.
- Sturdy plastic latches.
- Padlock clasp (padlock not supplied)
- Industrial quality tools



| CODE NO | HxWxD / mm | kg |
|---------|-----------------|-----|
| 8335988 | 494 x 263 x 250 | 1.9 |

TOOL BOX & ASSORTMENTS

8335975 31pc Tool Kit

- The perfect tool kit for professional electricians in the industry and trade
- Industrial quality tools



| CODE NO | HxWxD / mm | kg |
|---------|-----------------|-----|
| 8335975 | 494 x 263 x 250 | 5.7 |



8335979 43pc Tool Kit

- The perfect tool kit for professional mechanics in the industry and trade
- Industrial quality tools



| CODE NO | HxWxD / mm | kg |
|---------|-----------------|-----|
| 8335975 | 494 x 263 x 250 | 6.9 |



RS TOOL MODULES

SIZE: 370 mm x 175 mm x 35 mm

8335913

15pc T-Handle & Ballpoint L Hex Key Set



K10 (2.0, 2.5, 3.0, 4.0, 5.0, 6.0 mm) C-PLUS T-Handle Hexagon Keys
LT/900 (1.5, 2, 2.5, 3, 4, 5, 6, 8, 10 mm) Ball End Hexagon L Key Set

CODE NO

PIECES


PRICE/€

8335913

15

8335925

12pc Ratcheting Combination Wrench Set

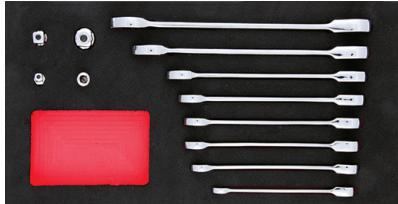

B05 (8, 10, 11, 12, 13, 14, 17, 19 mm) C-GEAR Ratcheting Combination Wrenches (Straight)
B05-14S (1/4"- 10 mm), **B05-38S** (3/8"- 13 mm),
B05-12S (1/2"- 19 mm) C-GEAR Socket Adaptors,
B05-14B (1/4"- 10 mm) C-GEAR Bit Adaptor

CODE NO

PIECES

PRICE/€

8335925

12

8335935

52pc 1/4" Drive Socket and Hex Key Set



C01-12 1/4" Drive Quick Release Reversible Ratchet

C01-20 1/4" Drive Spinner Handle

C01-80 1/4" Drive Universal Joint

C01-40 1/4" Drive Sliding T-Handle (115 mm)

C01-70 1/4" Drive Extension Bar (50, 150 mm)

C02-H (4, 4.5, 5, 5.5, 6, 7, 8, 9, 10, 11, 12, 13 mm) 1/4" 6-Point Socket

C04-H (4, 5, 5.5, 6, 7, 8, 9, 10, 11, 12, 13 mm) 1/4" 6-Point Deep Socket

C08-T (T10, T15, T20, T25, T30, T40) 1/4" Drive TORX Socket Bits

C08-H (3.0, 4.0, 5.0, 6.0, 8.0) 1/4" Drive Hexagon Socket Bits

C08-S (5.5 mm) 1/4" Drive Slotted Socket Bits

C08-PH (PH2) 1/4" Drive Phillips Socket Bits

C08-PZ (PZ2) 1/4" Drive Pozidriv Socket Bits

LT/9 (1.5, 2, 2.5, 3, 4, 5, 6, 8, 10 mm) 9 Piece Hexagon L Key Set (Short Arm-Matt Chrome)

CODE NO

PIECES


PRICE/€

8335935

52

8335919

10pc Precision Plier and Screwdriver Set

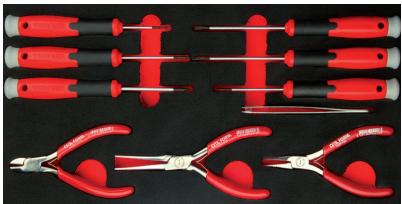

H30S-110SB Electronics Diagonal Cutter (Oval Head-Standard)

H33S-120 Electronics Short Needle Nose Pliers (Toothed Gripping Surface)

H35S-140 Electronics Long Needle Nose Pliers

H01 (1.5 x 60, 2.0 x 60, 2.5 x 80, 3.0 x 80 mm) Electronics Slotted Screwdrivers

H02 (PH0 x 60, PH0 x 60 mm) Electronics Phillips Screwdrivers

H41-06-0115 Tweezer (Stainless Steel)

CODE NO

PIECES

PRICE/€

8335919

10

8335929

4pc Circlip Pliers Set



E65-44-0180 180 mm External Circlip Pliers (Straight-with Spring)

E66-44-0180 180 mm External Circlip Pliers (Bent-with Spring)

E67-44-0180 180 mm Internal Circlip Pliers (Straight-without Spring)

E68-44-0180 180 mm Internal Circlip Pliers (Bent-without Spring)

CODE NO

PIECES

PRICE/€

8335929

4

8335938

3pc Pliers and Adjustable Wrench Set



E00-54-0250 250 mm Water Pump Pliers (Box Joint/PVC Sleeves)

E50-16-0240 240 mm Grip Plier (Curved Jaws)

B21-250B 250 mm Adjustable Wrench (Phosphated-PVC Grip)

CODE NO

PIECES

PRICE/€

8335938

3

8335922

16 Piece Combination Wrench Set



B01 (6, 7, 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 21, 22 mm) Combination Wrenches

CODE NO

PIECES


PRICE/€

8335922

16

8335931

3pc VDE Insulated Pliers Set

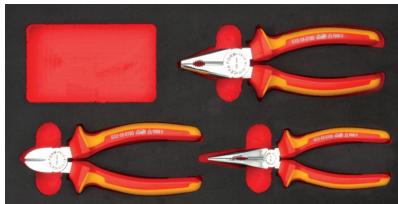

CODE NO

PIECES

PRICE/€

8335931

3

8335941

7pc Insulated Slotted/PH Screwdriver Set



1000 V EN 60900

G01 (3.0x100, 4.0x100, 5.5x125, 6.5x150 mm) C-PLUS VDE 1000V Insulated Slotted Screwdrivers

G02 (PH1x80, PH2x100 mm) C-PLUS VDE 1000V Insulated Phillips Screwdrivers

G106 Voltage Tester (VDE Approved-Long)

CODE NO

PIECES

PRICE/€

8335941

7

8335944
6pc Measuring and Cutting Tool Set

G40-48 (145 mm) Multi-Purpose Electrician's Shears

J06-250 (250 mm) English Pattern Snip

J45-07 Utility Knife (18 mm-Metal Body)

P05-0519 (5 m x 19 mm) Compact Tape Measure

P15-030 (30 cm) Stainless Steel Rule

P54-20S Feeler Gauge (20 Leaves - Metric)

CODE NO
PIECES
PRICE/€

8335944

6

8335953
11pc Standard and Needle File Set

J55-108H Hand File - Bastard, 200 mm

J56-108H Half Round File - Bastard, 200 mm

J57-108H Round File - Bastard, 200 mm

J58-108H Square File - Bastard, 200 mm

J59-108H Three Square File - Bastard, 200 mm

J75-R06 Needle File Set:

Flat File (7.3x1.8x160 mm), Hand File (7.3x1.8x160 mm), Three Square File (3.4x160 mm), Round File (Ø 4.0x160 mm), Square File (5.0x160 mm), Half Round File (7.3x2.6x160 mm)

8335966
2pc Climber and Stripper Set

E25-AT1 1/4" Drive Reversible Ratchet

E69-YT1 Automatic Wire Stripper

CODE NO
PIECES
PRICE/€

8335966

2

8335947
39pc Slotted/PZ Screwdriver and Bit Set

F10 (3.0x75, 4.0x100, 5.5x125, 6.5x150 mm)

C-PLUS Slotted Screwdrivers

F17 (PZ1x80, PZ2x100 mm) C-PLUS Pozidriv Screwdrivers

F26/BT 1/4"x100 mm C-PLUS Bit Driver


CB/ST31 31 Piece Bit Set

G106 Voltage Tester (VDE Approved-Long)

CODE NO
PIECES
PRICE/€

8335947

39

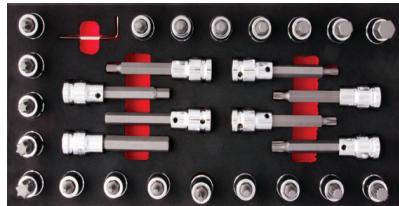8335957
29pc 1/2" TORX/Hex/XZN Socket Bits Set

C28S-T (T20, T25, T30, T40, T45, T50, T55, T60) x 30 mm

1/2" Drive TORX Socket Bits (Replaceable Bit) - Short

C28S-TL (T30, T40, T45, T50) x 75 mm

1/2" Drive TORX Socket Bits (Replaceable Bit) - Long

C28S-H (5, 6, 7, 8, 10, 12, 14 mm) x 30 mm

1/2" Drive Hexagon Socket Bits (Replaceable Bit) - Short

C28S-HL (6, 8, 10, 12 mm) x 75 mm

1/2" Drive Hexagon Socket Bits (Replaceable Bit) - Long

C28S-X (M05, M06, M08, M10, M12) x 30 mm

1/2" Drive XZN Socket Bits (Replaceable Bit) - Short

L (2.5 mm) Hexagon L Key (Short Arm)

8335969
5pc Hand Riveter Set

R01-260 Hand Riveter, 4 x 20 (Ø 2,4 - 3,2 - 4,0 - 4,8 mm) Rivets

CODE NO
PIECES
PRICE/€

8335969

5

8335950
23pc 1/2" Drive Socket Set with Ratchet

C21-12 1/2" Drive Quick Release Reversible Ratchet

C21-70 1/2" Drive Extension Bars (125, 250 mm)

C21-80 1/2" Drive Universal Joint


C21-40 1/2" Drive Sliding T-Handle (250 mm)

C22-H (8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 21, 22, 24, 27, 30, 32mm) 1/2" Drive 6-Point Sockets


CODE NO
PIECES
PRICE/€

8335950

23

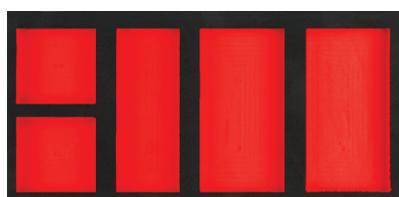8335963
5 Division EVA Module


This module is especially useful to complete 2 drawer modules to 3 modules, can be used for storage of fasteners such as screws, nuts, washers etc.

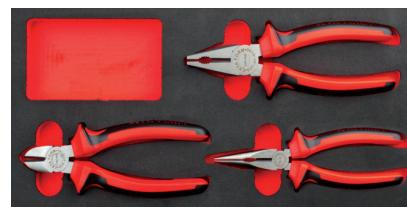8335972
3pc Softgrip Pliers Set

E01-41-0180 180 mm Combination Pliers (Polished Finish/DuoTech Handles)

E06-41-0160 160 mm Diagonal Cutter (Polished Finish/DuoTech Handles)

E15-41-0160 160 mm Long Nose Pliers (Polished Finish/DuoTech Handles)

CODE NO
PIECES
PRICE/€

8335972

3

KITS FOR SECTORS
Mechanic

Maintenance

Electrician

General Purpose