



DIAZED FUSE LINK 500V F.CABLE AND LINE PROTECTION OP.CL.GL,SZ.DII,THREAD E27,20A

Similar to image

Technical data:

Color coding of the fuse link		blue
Current / for AC / rated value	A	20
Tripping characteristic class		others
Size of the fallback-system / acc. to DIN EN 60269-1		DII
Supply voltage		
• for AC / rated value	V	500
• for DC	V	500
Switching capacity current		
• in accordance with IEC 60947-2 / rated value	kA	50
• with DC / in accordance with IEC 60947-2 / rated value	kA	8
Ambient temperature		
• minimum	°C	-5
• maximum	°C	40

Certificates/approvals:

General Product Approval

Declaration of Conformity

Test Certificates



KEMA

[ROSTEST](#)



VDE



ÖVE

[Manufacturer](#)

[Manufacturer](#)

Shipping Approval



GL

Further information:

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<http://www.siemens.com/lowvoltage/mall>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)


<http://support.automation.siemens.com/WW/view/en/5SB271/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=5SB271

CAX-Online-Generator

<http://www.siemens.com/cax>

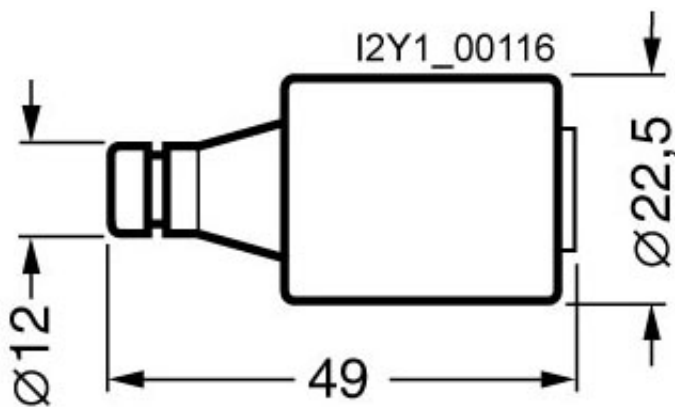

last change:

Aug 26, 2011