

Features

- 230V AC and 24V AC-DC operating
- 0,1 sec 999 minutes(adjustable)
- With trigger
- Panel type timer
- 48X48 dimension
- 1relay out
- Trigger input

RS PRO Timer Relays

RS Stock No.: 0434508



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

- *Timer relays are designed for use in all areas requiring time-dependent control.*
- *Control the loads depending time*
- *Motoring time on display screen*
- *With trigger to control time start*
- *Universal operating voltage*
- *Out led and trigger led is on the screen*

General Specifications

Product type	Timer Relays
Supply voltage	External
Operating voltage	230V AC , 24V AC-DC
Mode of operation	On delay and off delay
Number of timer functions	2
Max contac current	5A 230V AC
Max voltage	240V AC
Time increment	Sec, min
Function measured	Time
True RMS	YES
Display type	Display screen
Operating temperature	-20, +55
Storage temperature	-30, +80
Surge protection	YES
Mounting type	Assembled on the panel
Connection type	Terminal
Number of contacts	1NO+1NC
Monitoring application	Time
Electrical phase	L+N
Time range	0,1 sec – 999 min
Mode of operation	On delay and off delay

Mechanical Specifications

Width	69 mm
Length	48 mm
Height	48 mm
Weight	< 250 gr

Electrical Specifications

Operating voltage	3X380V AC
Frequency	50/60 Hz
Safety Category voltage	CATII
Cable diameter	2,5mm


Protection Category

IP rating	IP20 body
-----------	-----------

Approvals

Compliance/Certifications	CE-UKCA
Hazardous Area Certification	ROHS-3

Wiring Diagram

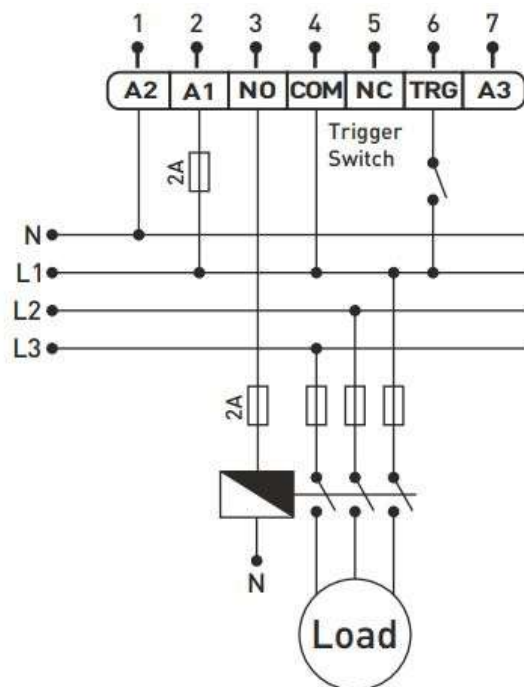

Similar Products

Stock No.	Product Name	Attribute 1	Attribute 2	Attribute 3
0434509	Timer Relays	On-off cycle timer	Useable for all industrial areas	99 min time adjustable