

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer


This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts







Customers Also Bought




TE Part #1954640-1
Plug Kit,USB Series B




TE Part #6609973-4
6IK1=F7247Z




TE Part #9-1768018-0
EET-3270P-8A




TE Part #1SNG626176R0000
EP-SGL-PG29-GR-B




TE Part #5-1879208-5
CPF 0402 1K8 0.1% 25PPM 1K RL




TE Part #6-1624113-0
3650 0805 0.43uH 5% 2K RL




TE Part #91548-1
CCII HD-20 PIN SKT 28-20 ASSY



TE Part #1-1337452-0
BNC Ins BHSkt 50Ohm Nickel Gol



TE Part #HPP805A031
HM1500LF HUMIDITY MODULE

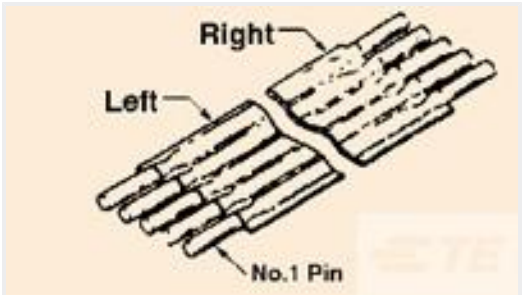

TE Part #3-1437142-6
FSN-22A-16=NOMEX FS STD

Documents

Product Drawings

USB, A-B, 28/26, WHITE, 1.3M

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1487587-2_G_c-1487587-2-g.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1487587-2_G_c-1487587-2-g.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1487587-2_G_c-1487587-2-g.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.



Product Specifications

Application Specification

English