


Actuator

704.743.8

Distribution by
Rs-online<https://rs-online.eao.com/p/704.743.8>

Your product:

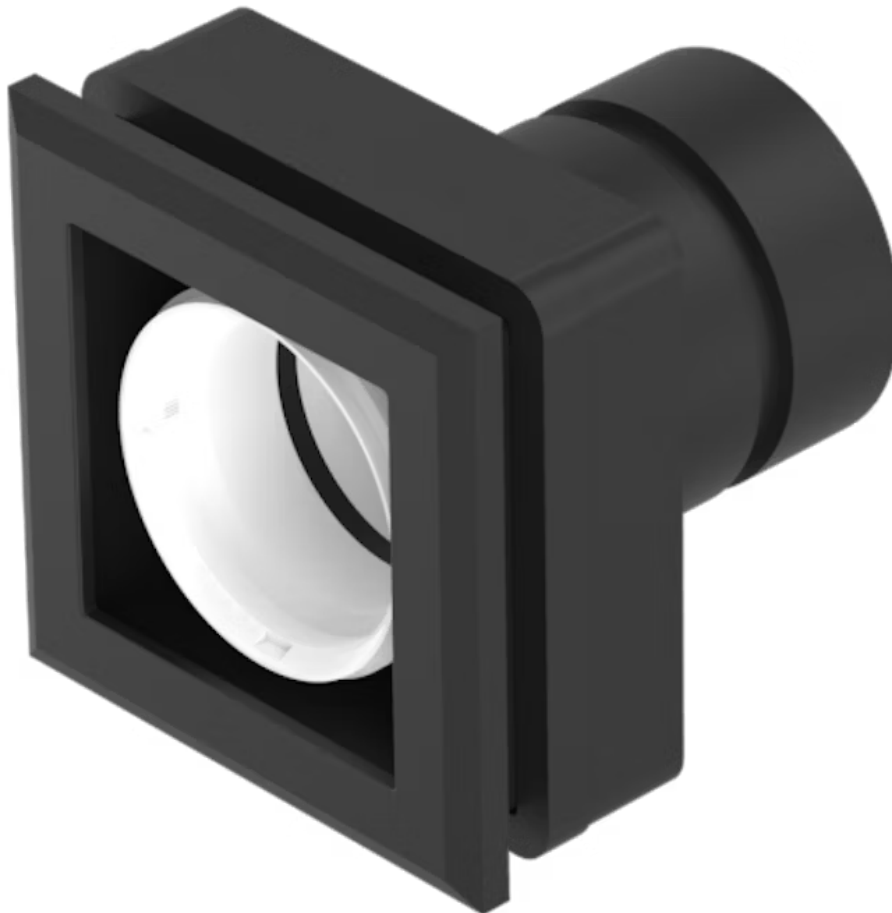

704.743.8 Actuator

FRONT

Front dimension:	35 mm x 35 mm
Front form:	Square
Front bezel colour:	Silver
Front bezel material:	Plastic

MOUNTING

Mounting cut-out:	30 mm x 30 mm
Mounting type:	Panel mounting

ELECTRICAL CHARACTERISTICS

Standards:	The switches comply with the "Standards for low-voltage switching devices" DIN EN 60947-1
------------	---

MECHANICAL CHARACTERISTIC

Weight:	0.02 kg
---------	---------

AMBIENT CONDITION

IP Protection:	IP65 front side
Operating temperature:	- 40 °C ... + 55 °C
Storage temperature:	- 40 °C ... + 85 °C

CERTIFICATE

REACH:	REACH compliant
--------	-----------------

RoHS:

RoHS compliant

OTHER

Short Description:

Actuator, 30 mm x 30 mm, 35 mm x 35 mm, Square, Silver, Plastic


Housing colour:

Black


Housing material:

Plastic

Wiring diagrams:

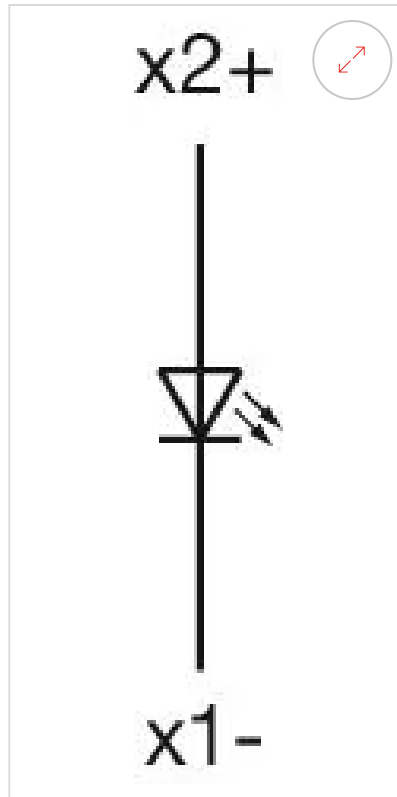

Mounting cut-outs:

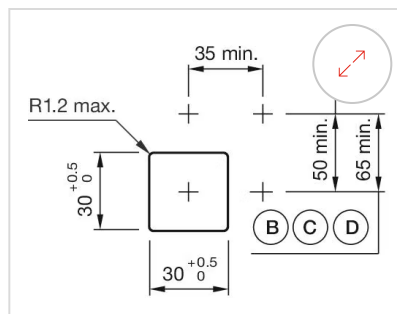


A = Screw terminal

B = Push-in terminal (PIT)

C = Plug-in terminal 6.3 mm x 0.8 mm


D = Double plug-in terminal 6.3 mm x 0.8 mm

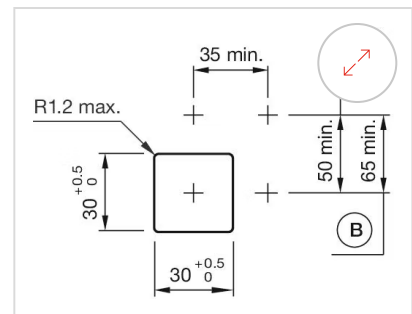


A = Screw terminal

B = Push-in terminal (PIT)

Dimension drawings:

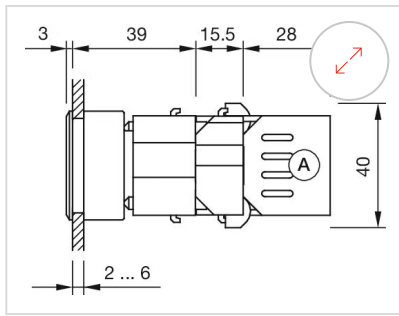

A = Screw terminal

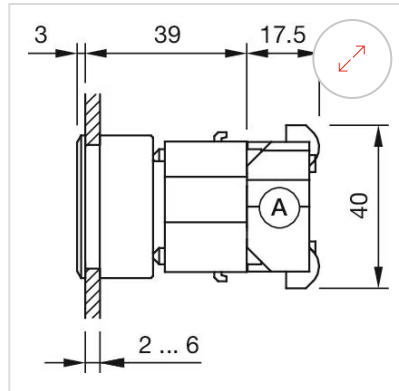

A = Screw terminal