



Data sheet analogue high torque cordless torque wrench LDA3

Powerful tightening and loosening from 90 - 8,000 NM

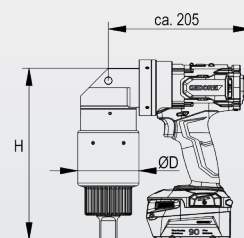

Series LAW3

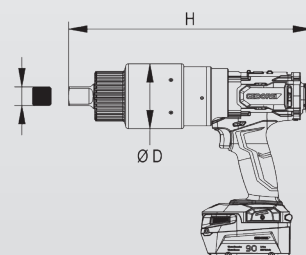

Series LDA3

Technical Data

Type	N-m min ^{*1} /max ^{*2}	~ U/min	■	Ø D mm	H mm	kg ^{*3}
LDA3-05	90 - 500	43	3/4"	80	271	3.6
LDA3-07	120 - 700	27	3/4"	80	304	4.1
LDA3-12	150 - 1.200	20	3/4"	80	304	4.1
LDA3-15	220 - 1.500	14	1"	88	319	5.2
LDA3-22	250 - 2.200	11	1"	88	329	5.9
LDA3-32	350 - 3.200	6,3	1"	88	360	6.3
LDA3-40	500 - 4.000	5,5	1"	88	360	6.3
LDA3-60	700 - 6.000	3,7	1½"	102	376	8.1
LDA3-80	900 - 8.000	2,5	1½"	142	408	10.6
LAW3-05	90-500	43	3/4"	80	187	4.7
LAW3-12	150 - 1.200	20	3/4"	80	223	5.3
LAW3-15	220 1.500	14	1"	88	235	6.4
LAW3-22	250 - 2.200	11	1"	88	255	7.0
LAW3-32	350 - 3.200	6,3	1"	88	279	7.5
LAW3-40	500 - 4.000	5,5	1"	88	279	7.5
LAW3-60	700 - 6.000	3,5	1½"	102	291	9.3

Other torque on request

- » *1 Minimum torque in 2nd gear
- » *2 Maximum torque in 1st gear
- » *3 Without reaction arm with battery
- » Battery: 720g
- » The vibration is less than 2.5 m/s²
- » Continuous sound pressure level according to DIN 45635 < 80 dB (A)
- » Other torque ranges on request
- » All specifications without guarantee
- » Subject to technical changes