


## SWEDISH MODEL PIPE WRENCHES WITH THIN, SHAPED JAWS BENT TO 45°

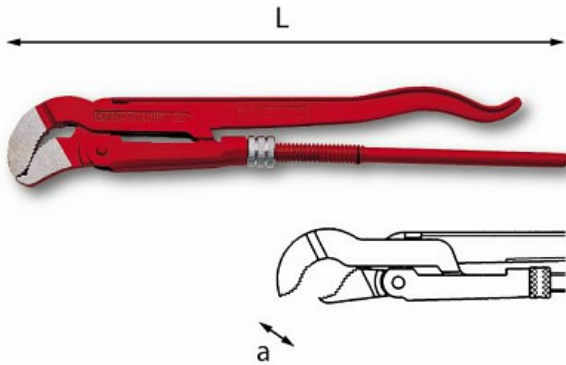

### 310 N

- Chrome Vanadium steel

### Family details

Code	L mm	Hose capacity	a mm	Quantity for packaging
U03100001	270	1/2	25	1
U03100002	340	1	40	1
U03100003	430	1 1/2	55	1
U03100004	550	2	67	1
U03100005	700	3	103	1

### Sets / Compositons

Stanley Black & Decker Italia S.r.l.

Sede legale: Via Energy Park 6 - 20871 Vimercate (MB)  
 Sede operativa: Via Volta 3 - 21020 Monvalle (VA) Italia  
 Partita IVA e C.F.: 03225990138

 
**StanleyBlack&Decker**

Società a Socio Unico soggetta a coord. e controllo da parte di Stanley Black & Decker, Inc.  
 Capitale Sociale I.V. € 12.000.000

## Articles



496 E4 - Assortment for industrial maintenance (256 pcs.)



496 E6 - Assortment for industrial maintenance (124 pcs.)



496 E7 - Assortment for industrial maintenance (209 pcs.)



496 EP6 - Assortment for industrial maintenance (112 pcs.)



496 L - Assortment for plumbers (25 pcs.)

## Spare parts

### Articles



310 CN - Spare rollers