


DX06WB012N Datasheet

Product Name // DX06WB012N, 6mm Diameter, Wire Leads 200mm, Blue, 12V, Nickel Plated Brass

 View Product Page

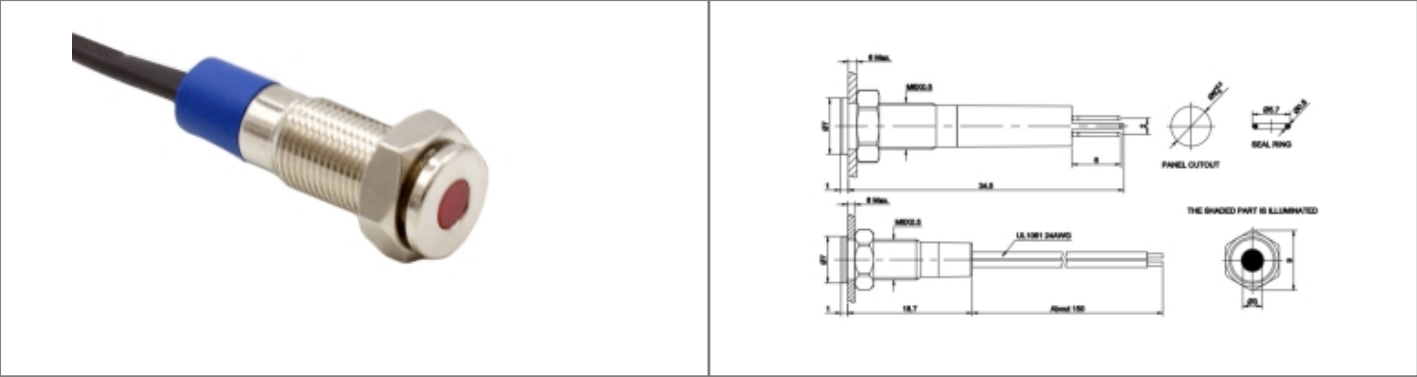

// Product Description:

- | | |
|--|---|
|  DX Series |  Blue |
|  6mm Diameter |  12V |
|  Wire Leads 200mm |  Nickel Plated Brass |

// General Information:

Product Display Title:	6mm Vandal Resistant Indicator DX Range
Product Family:	Indicators
Product Series:	6mm Vandal Resistant Indicator DX Range
Bezel Finish:	Polished
Body Colour:	Nickel
Body Material:	Brass
Body Material Type:	Metal
Diameter:	6mm
Dielectric Withstanding Voltage:	1500V
Function:	Vandal Resistant Indicator
Illumination Colour:	Blue
Illumination Voltage:	12V
Indicator Profile:	Flat-round
Insulation Resistance:	≥100MΩ(500VDC)
Ip Rating:	IP67
Material Finish:	Polished
Max Operating Temperature:	55°C
Min Operating Temperature:	-25°C
Max Panel Thickness:	6mm
Panel Cut Out:	6mm Diameter circle
Rohs Compliant:	Yes
Thread Size:	M6 X 0.5

// Product PDF Links

 6mm & 8mm Vandal Resistant...

// Product 3D CAD Model Links

 DX06WB012N3D CAD Model



Have a question or project enquiry
you'd like to talk to us about?



Click Here To Contact Us