


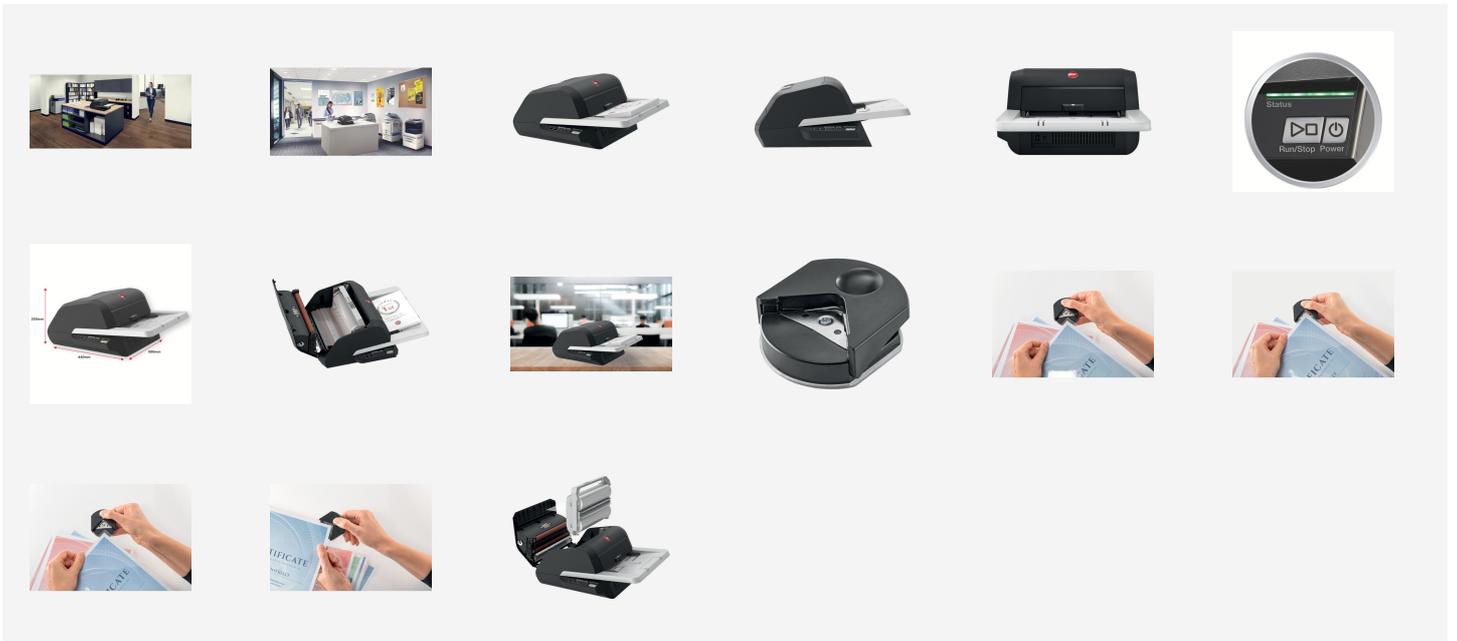

## GBC Foton 30 Automatic A3 Laminator

Save 98% of your time laminating with the worlds first fully automatic office laminator. You simply load your documents in the Auto Feed tray, press the start button and it automatically laminates. Load, press, done! Easy load cartridge technology for perfect laminated documents time after time. Ideal for offices with regular lamination requirements.



## Attributes

- Automatically laminates up to 30 A4 or A3 documents at a time
- Easy load film cartridges will laminate up to 250 A4 documents - available in 75, 100 & 125 micron
- Automatic auto feed paper alignment for perfect laminated documents every time
- Manual lamination mode for heavy weight paper or non standard shaped documents, up to 250gsm
- Included in the box so you're ready to laminate; 1x 75 micron cartridge and 1x corner rounder for perfectly finished documents
- Intuitive control panel allows easy switching between automatic and manual mode settings
- Low film indicator light to let you know when cartridge needs replacing
- Intelligent power save function
- 2 year warranty



## Specifications

Number	4410011
Colour	-----
Dimensions (W x H x D)	580 x 250 x 440 mm
Laminating Speed (mm/min)	700
Power Supply	220/240 V AC
Warm up Time (min)	4
Heating System	2 internally heated & 2 cold rollers
Operation Mode	4 roller, cartridge, temperature controlled
Max. Laminating Width (mm)	297
Max. Laminating Thickness (mm)	0.5
Max. Pouch Thickness (microns)	125
Power Consumption (W)	1084
Dimensions (with Tray) mm	570(W) x 245(H) x 478(D)
Anti-Jam Technology	Manual Release
Approx. lamination time (A4)	26 secs (A4 75 microns)
Photo friendly	Yes
Period of Warranty (Years)	2
Type	Automatic
Weight	11582 g
Pallet quantity	6
EAN code	5028252597302