


DATASHEET



FLP200A

230V IP65 200W LED Floodlight 6000K

www.mlaccessories.co.uk

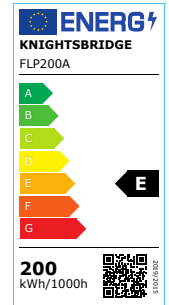

MLA PART CODE	FLP200A
DESCRIPTION	230V IP65 200W LED Floodlight 6000K
NET WEIGHT (KG)	3.5
FINISH	Anthracite
DIFFUSER	Clear
DIMENSIONS (MM)	Height - 237 Width - 360 Depth - 73 Projection - 200
CONSTRUCTION	Construction - Die-cast aluminium
CLASS	I
IP RATING	IP65
WATTAGE (W)	200
LAMP TECHNOLOGY	LED
LAMP INCLUDED	Yes
LUMENS (LM)	18400
LUMEN TOLERANCE	5%
EFFICACY (LM/W)	95.1
CIRCUIT WATTAGE (W)	195
CCT	6000K
LIGHT COLOUR	Daylight
CRI	>85
SDCM	<6
RUNNING CURRENT (A)	0.86
DISPLACEMENT FACTOR	>0.7
SVM	3.2
PST-LM	0.74
BEAM ANGLE (DEGREES)	110
LIFE SPAN (HRS)	30,000
L70B50 LIFESPAN (HRS)	54,000

LED COMPATIBLE	Yes
DIMMABLE	No
OPERATING TEMPERATURE	-20~40°C
INPUT VOLTAGE	230V 50Hz
CABLE GLAND INCLUDED	Compression gland
WARRANTY	3year(s)
MANUFACTURED IN ACCORDANCE WITH	BS EN 60598
ORIGIN OF MANUFACTURE	China
DECLARATION OF CONFORMITY (HELD ON FILE)	Yes
EAN	5056270800609

Date Created: 09/02/2022 11:48

