




## RoBust LED Torch Light 5W 6500K 550lm IP67 3xAAA

Article number: 147111

BAI RoBust LED Torch Light 5W 6500K 550lm IP67 3xAAA (not included) 141x35mm Black aluminium housing Adjustable beam angle 60°/20° Switch 550lm/180lm

Compact flashlight with impressive power. This compact and easy-to-carry flashlight is a must-have for both private and professional use whenever darkness strikes and no power supply is available. Smaller than your smartphone, yet delivering an impressive 550 lumens of bright light. With its IP67 rating, this torch performs reliably in wet and demanding conditions. The bright white light (6500K) ensures excellent visibility, while the adjustable beam can be smoothly changed from 60° to 20°. Powered by three AAA batteries (not included), the flashlight offers a runtime of 4.5 to 15 hours, depending on the selected mode. A powerful, dependable light source you can count on anywhere.

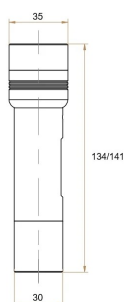

### General ETIM properties

|               |                                                  |
|---------------|--------------------------------------------------|
| ETIM group    | Luminaires                                       |
| ETIM class    | Flashlight                                       |
| Name          | RoBust LED Torch Light 5W 6500K 550lm IP67 3xAAA |
| Brand         | Bailey                                           |
| Productseries | RoBust LED charge                                |
| Producttype   | TORCH LIGHT 5W AAA                               |

## ETIM specifications

|                           |                      |
|---------------------------|----------------------|
| Material                  | Aluminium            |
| Model                     | Bar-shaped lamp      |
| Luminous flux adjustable  | Positions            |
| Luminous flux [lm]        | 180 - 550            |
| Length [mm]               | 141                  |
| Rechargeable              | No                   |
| Battery type              | Micro                |
| Housing colour            | Black                |
| Degree of protection (IP) | IP67                 |
| Batteries included        | No                   |
| Lamp type                 | LED not exchangeable |
| With light source         | Yes                  |
| Weight total [g]          | 148                  |
| ANSI                      | AAA                  |
| Number of batteries       | 3                    |