


PX0725/30/63 Datasheet

 [View Product Page](#)

Product Name // IEC Connector Snap Fit To Panel Outlet 2
Pin PX0725 Series 3mm Panel Black 6.3mm Tab Termination
EN60 320-2-2 Standard Sheet H Class II

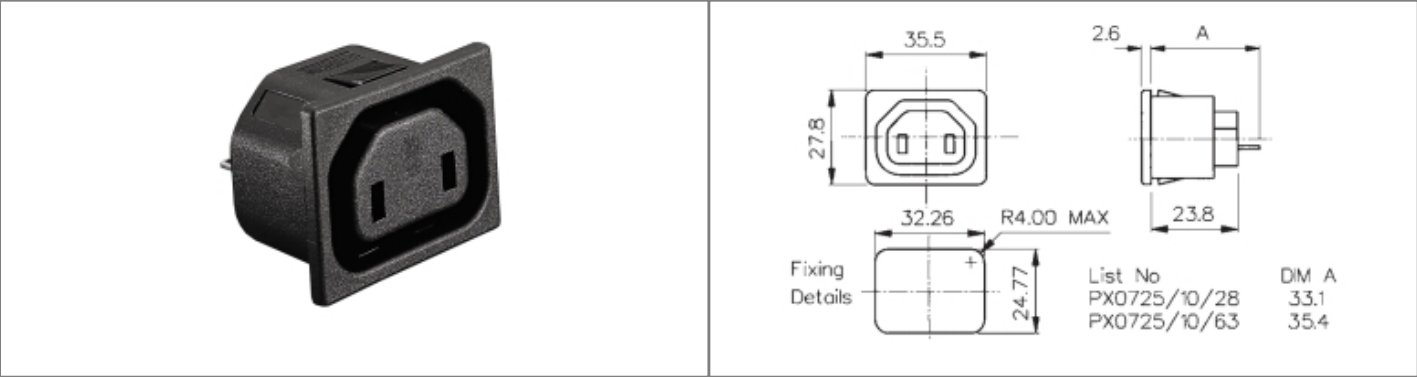

// Product Description:

- Snap Fit To Panel Mount IEC Outlets
 - EN60 320-2-2 Standard Sheet H Class II
 - Two Pin Class II (no Earth pin)
 - Choice of panel thickness depending on part code: /10 - 1mm, /15 - 1.5mm, /20 - 2mm, /30 - 3mm
- Choice of Termination depending on part code: /28 - 2.8mm Solder Tag, /48 - 4.8mm Tab, /63 - 6.3mm Tab
 - Choice of colour depending on part code: /WH - White, /GY - Grey, no suffix - Black (some approvals apply to specific colour and/or Termination choices only - see data for details)
 - Insulation Boot for rear of connector available separately (part code 12075)

// General Information:

Product Display Title:	Snap Fit To Panel Mount IEC Outlets
Product Family:	IEC Connectors
Product Series:	IEC60320 Main Inlets and Outlets
Approvals:	CSA, ENEC, UL, VDE
Body Material:	Nylon 66
Current Max:	10A, 15A
Flamability Rating:	UL94V-0
Function:	Panel Mount Connector
Iec Connector Colour:	Black
Iec En60620 Type:	EN60 320-2-2 Standard Sheet H Class II
Max Operating Temperature:	+70°C
Min Operating Temperature:	-40°C
Max Panel Thickness:	3mm
Min Panel Thickness:	3mm
Number Of Contacts:	2 Contacts
Voltage Max:	250V

// Product PDF Links

 [IEC Connectors product data](#)

// Product 3D CAD Model Links

 [PX0725/30/633D CAD Model](#)