


Self-aligning ball bearings, cylindrical and tapered bore



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
17	47	19	12,7	3,4	0,18	-	11000	0,16	2303 E-2RS1TN9

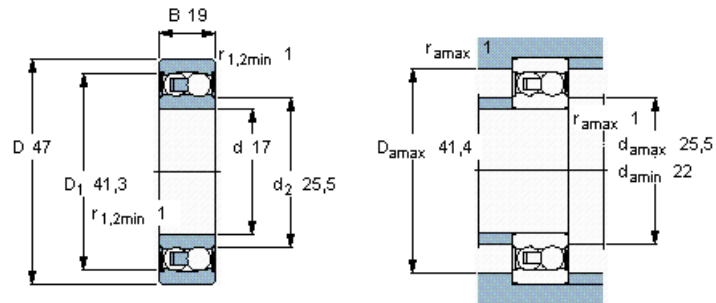

Calculation factors

- e 0,3
- Y_1 2,1
- Y_2 3,3
- Y_0 2,2