



SIVACON, side panel / rear panel, Closed, IP40, H: 2200 mm, W: 800 mm, RAL 7035

Model	
product brand name	SIVACON
product designation	Side panel/rear panel
design of the product	Closed
design of the surface	Powder-coated
design of the product EMC version	No

Protection class	
protection class IP	IP40

Appearance	
RAL color number	RAL 7035
color	light grey

Product details	
product component	
• cable entry	No
• lock	No

Mechanical Design	
height	2 200 mm
width	800 mm
depth	800 mm
material	steel

Approvals Certificates		
General Product Approval	Test Certificates	other



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other	Environment
-------	-------------

[Miscellaneous](#)


Siemens
EcoTech



[Environmental Confirmations](#)

Further information
Information on the packaging https://support.industry.siemens.com/cs/ww/en/view/109813875 Information- and Downloadcenter (Catalogs, Brochures,...) http://www.siemens.com/lowvoltage/catalogs

Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1280-2UW60-1C>
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8MF1280-2UW60-1C>
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1280-2UW60-1C
CAx-Online-Generator
<http://www.siemens.com/cax>
Tender specifications
<http://www.siemens.com/specifications>

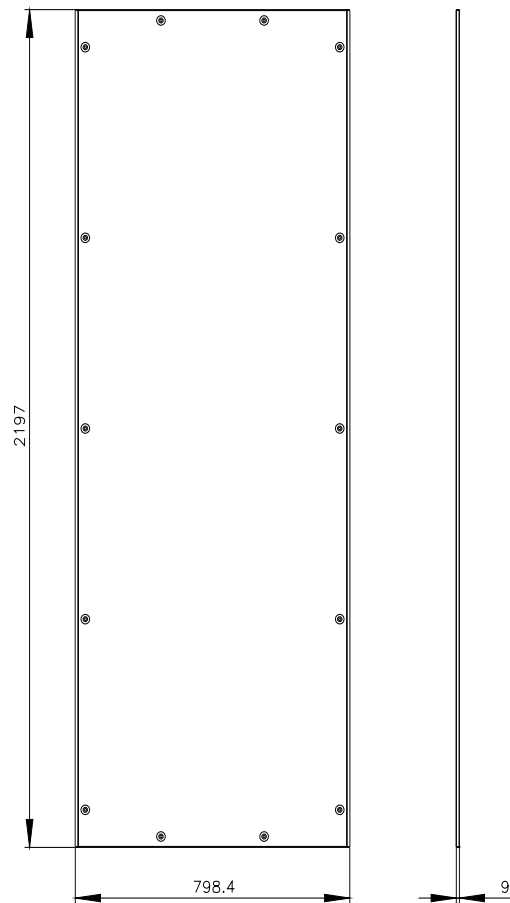

last modified: 5/24/2025

