


## Deep groove ball bearings, double row



Principal dimensions			Basic load ratings		Fatigue load limit $P_u$	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
25	52	18	19	14,6	0,62	20000	11000	0,16	4205 ATN9

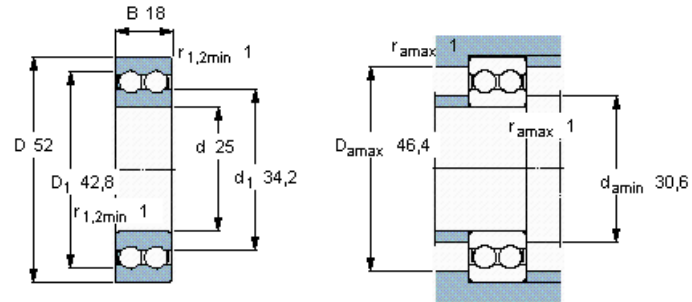

### Calculation factors

$k_r$  0,05  
 $f_0$  14