

Part Number:1202510049

Status:Active

Overview:Brad Ultra-Lock Connection System


Description:MPIS Ultra-Lock (M12) Passive Junction Box, Top-Mount, 4 Ports / 5 Poles, PNP Sensor LED Indicators, 5.0m Length, Dual IO Per Port

Documents:

図面 (PDF)

RoHS Certificate of Compliance (PDF)

一般	
IP Rating	IP67
概要	Brad Ultra-Lock Connection System
製品名	Ultra-Lock (M12)
UPC	193264490042
機械的性能/材質	
Bus I/O	Ultra-Lock (M12)
Cable Connector Orientation	ストレート
ケーブル長	5.0m
Home Run Cable Length	5.0m
Home Run Connector	N/A
Home Run Interface	Pigtail
Keyway	シングル
LED Indicator	PNP Sensors
Material - Cable Jacket	TPU
Material - Housing	PBT
材質 - 金属部	銅合金
材質 - 嵌合部メッキ	金
Net Weight	541.000/g
実装形態	Top-Mount
Poles	5
Poles (wired)	5
ポート	4
使用温度範囲	-25° C to +85° C
ケーブル種別	TPE
Wiring Configuration	Dual I/O per Port
電氣的性能	
最大定格電流	3.0A per port, 9.0A per module
Functional Wiring	PNP
最大定格電圧	10-30V DC
参考情報	
Engineering Number	BKB405P-FBW-05
図面・仕様書情報	
製品図面	1202510046-000

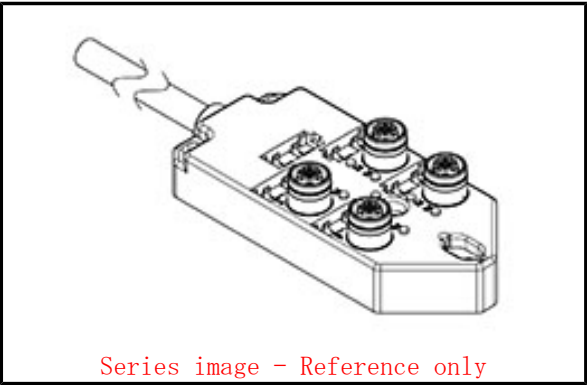

EU ELV	
Compliant with Exemption 3	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Compliant with Exemption 3
RoHS Phthalates	Not Contained

Search Parts in this Series

120119 Series