


Geberit Mapress Carbon Steel bend adaptor 90° with female thread

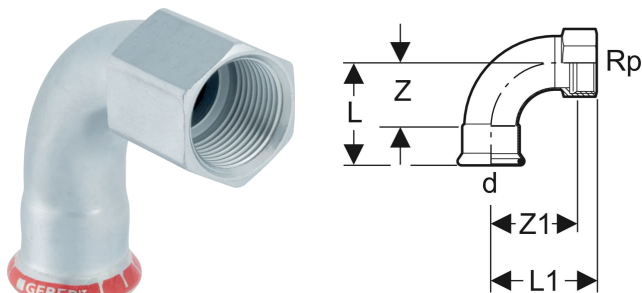

Example image

APPLICATION PURPOSES

- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water ≤ 120 °C
- For extinguishing water (wet)
- For sprinklers (wet)
- For compressed air (oil purity class 3)
- For technical building systems, industry and shipbuilding

CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed
- Outside zinc-plated
- Seal ring made of CIIR, black
- Pressing socket with transparent protection plug

TECHNICAL DATA

Product material Non-alloy steel 1.0034 E195 (EN 10305)

ACCESSORIES

- Fastening for Geberit Mapress elbow adaptor 90°

INFO

- Dimension changes of individual articles as per table will be completed by end of December 2026

Art. no.	DN	d, ø mm	Rp "	arc °	L cm	L1 cm	Z cm	Z1 cm
20551	10	12	3/8	90	4.2	4.1	2.5	3
20552	12 / 10	15	3/8	90	4.9	4.5	2.9	3.4
20553	12 / 15	15	1/2	90	4.9	4.8	2.9	3.3

Art. no.	DN	d _e mm	R _p "	arc °	L cm	L ₁ cm	Z cm	Z ₁ cm
20555	15	18	1/2	90	5.3	5.2	3.3	3.7
20557	20	22	3/4	90	6.1	6	4	4.4
20558	25 / 15	28	1/2	90	7.2	6.5	4.9	5
20559	25	28	1	90	7.2	6.6	4.9	4.7
20560	32	35	1 1/4	90	6.8	7.5	4.2	5.4
20561	40	42	1 1/2	90	8	8.4	5	6.3
20562	50	54	2	90	10	10.4	6.5	7.8