


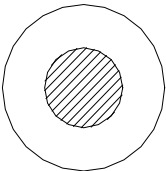

Datasheet

Product Name:	UL1213 22AWG
Product Discription:	UL1213 22AWG
Specification No.:	
Customer's Name:	

Description		Construction			
Rated Voltage:	Not specified	Conductor	Stranded Sliver plated copper		
Rated Temperature:	105°C, 60 °C Oil	Size(AWG)	22		
Reference Standard:	UL758	Construction(±0.008mm)	19/0.16		
Cross Section		Stranded Dia.(mm)Ref.	0.76		
		Insulation Material	PTFE		
		Insulation Color	ANY COLOR		
		Ave Thickness(mm)	0.2		
		Insulation Dia.(±0.10mm)	1.27		

Marking	Remark:
No marking on the cable jacket, have UL label on the Reel.	8739715 Grey 8739712 Orange 8739703 Yellow 8739719 Violet 8739709 Brown

Applications	Characteristics	Customer Approve
Internal wiring where not subjected to mechanical abuse, Oil Resistant 60 deg C.	Test Item	Standard Value
	Test Material	PTFE(ROHS)
	Insulation resistance(20°C MΩ*m)	1000
	Vol. Tesr(AC.V.60S) (V)	2000
	Flammability Test	Horizontal flame
	Max.DC Resistance(20°C Ω/km)	48.5(MAX)

Revisions				
Version	Description	Drawn by	Approved by	Date
0	New document issue	Danniel	Jason	24/04/2015

Seal & Stamp

Signature:

Date: