


Geberit Mapress Copper flanged stub with plain end, for loose flange PN 10/16

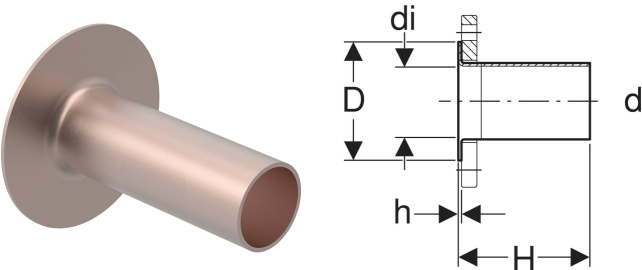

Example image

APPLICATION PURPOSES

- For cold and hot potable water
- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water ≤ 120 °C
- For service water and process water
- For compressed air (oil purity class 0–3)
- For negative pressure
- For inert gases (e.g. nitrogen)

- For technical building systems, industry and shipbuilding

CHARACTERISTICS

- Suitable for loose flange, in accordance with EN 1092-1, flange type 02

TECHNICAL DATA

Product material	Cu-DHP copper CW024A (EN 1412)
------------------	--------------------------------

TO ORDER ADDITIONALLY

- Geberit Mapress loose flange PN 10/16

ACCESSORIES

- Geberit flange gasket, fibre composite material PN 10/16

Art. no.	DN	d, ø mm	di, ø mm	D cm	H cm	h cm	PN bar
63706	25	28	25.2	6.8	8.1	0.2	10 / 16
63707	32	35	32	7.8	9.3	0.2	10 / 16
63708	40	42	39	8.8	10.9	0.2	10 / 16

<i>Art. no.</i>	<i>DN</i>	<i>d_ø</i> <i>mm</i>	<i>d_i ø</i> <i>mm</i>	<i>D</i> <i>cm</i>	<i>H</i> <i>cm</i>	<i>h</i> <i>cm</i>	<i>PN</i> <i>bar</i>
63709	50	54	51	10.2	10.9	0.2	10 / 16
63710	65	66.7	62.7	12.2	14.2	0.2	10 / 16
63711	65	76.1	72.1	12.2	14.5	0.2	10 / 16
63712	80	88.9	84.9	13.8	15.2	0.2	10 / 16
63713	100	108	104	15.8	17.4	0.3	10 / 16