

# GROMMETS & BUSHINGS, LED SPACERS AND INSULATORS


G

Part No.	Part No.	"A" mm	"B" mm	"C" mm	"D" mm	Material	Panel thickness range
NGS-1	SNGS-1	3.2	0.8	0.8	0.5	Nylon (RMS-21)	to 0.9
NGS-2	SNGS-2	4.4		2.8	0.9		0.9 - 1.8
NGS-2.5	SNGS-2.5				1.5		1.8 - 2.7
NGS-3	SNGS-3	4.8	1.2	4.0	2.7		2.7 - 4.2
NGS-4	SNGS-4			4.8	4.2		4.2 - 4.7
NGS-5	SNGS-5			6.4	4.7		4.7 - 6.4
PGS-1	SPGS-1	3.2	0.8	0.8	0.5	Polyethylene (RMS-13)	to 0.9
PGS-2	SPGS-2	4.4		2.8	0.9		0.9 - 1.8
PGS-2.5	SPGS-2.5				1.5		1.8 - 2.7
PGS-3	SPGS-3	4.8	1.2	4.0	2.7		2.7 - 4.2
PGS-4	SPGS-4			4.8	4.2		4.2 - 4.7
PGS-5	SPGS-5			6.4	4.7		4.7 - 6.4



## NGS/PGS/ SNGS/SPGS

CONTINUOUS GROMMET STRIP

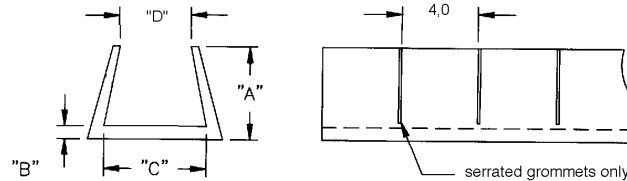

Material: see table; natural or black  
add suffix "B" for black  
Std. Pk.: 30.3 m per roll

Note:

