

WINSTA® MIDI


Snap-In Plugs and Frames, 3-Pole

PUSH-IN CAGE CLAMP®

3

99

<p>2 x 0.5 ... 4 mm² ① 250 V/4 kV/3 I_N 25 A</p> <p>9 mm / 0.35 in.</p> <p>② Approvals</p>	<p>2 x 20 ... 12 AWG</p>	<p>2 x 0.5 ... 4 mm² ① 250 V/4 kV/3 I_N 25 A</p> <p>9 mm / 0.35 in.</p> <p>② Approvals</p>	<p>2 x 20 ... 12 AWG</p>	<p>Snap-in frame – for 3-pole sockets and plugs (see page 95) Plate thickness: 1 ... 3 mm</p>
---	--------------------------	---	--------------------------	---

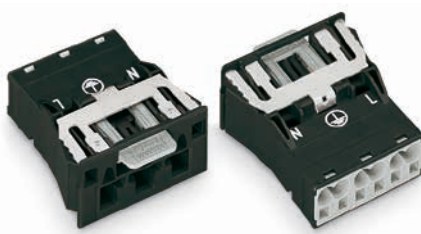

3

Color	Item No.	Pack. Unit	Color	Item No.	Pack. Unit	Color	Item No.	Pack. Unit
Plug			Plug with direct ground contact			Snap-in frame, 3-pole		
● black	770-713	100	● black	770-713/007-000	100	black	770-318	100
○ white	770-733	100	○ white	770-733/007-000	100	white	770-338	100
● red	770-2313	100	● red	770-2313/007-000	100			
● orange	770-2353	100						

Item-Specific Accessories

Lockout cap, for plug, separable, 5-pole



yellow 770-360 100

Lockout cap, for plug, separable, 5-pole



yellow 770-360 100

Locking lever, oversized,



tool operated
gray 770-140 100 (4x25)

Operating tool, partially insulated



3-way
770-383 1

Coding pin, for plug (A and B coding)



gray 770-401 100

Accessories, 770 Series

Lockout cap, for cutout, 3-pole




black 770-643 100
white 770-693 100

Lockout cap, for cutout, 3-pole



black 770-643 100
white 770-693 100

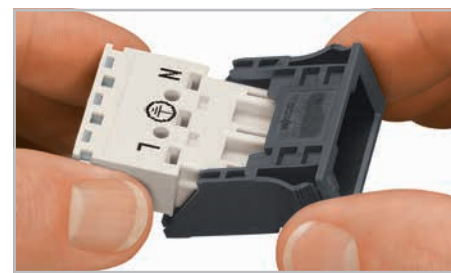

Insert the socket or plug into the frame (observe the "TOP" marking on the frame!). Snap the assembled unit into the cutout.

Dimensions

