


Illustration shows L.H. version

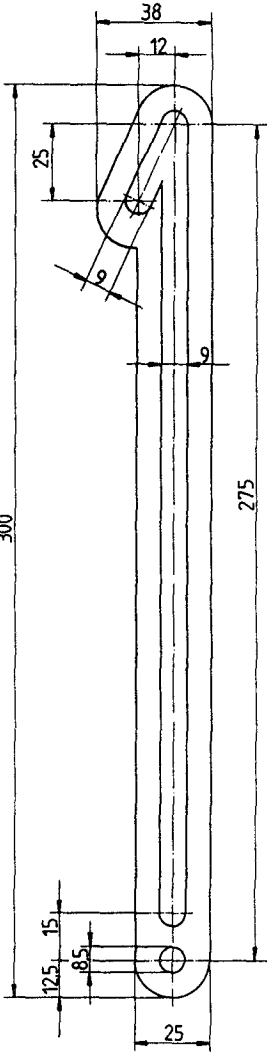

Clap holder

Dim. mm	Material mm	Version	No.
200	15 x 2	Steel/nickel plated	0.83.0001.3 right 0.83.0001.4 left
250	15 x 2	Steel/nickel plated	0.83.0003.3 right 0.83.0003.4 left
350	15 x 3	Steel/zinc and passivate	0.83.0005.3 right 0.83.0005.4 left

Door stay

Material 4 mm, steel, zinc and passivate

No. _____
0.83.0008.0

As special execution with economic ordering quantities also available in stainless steel. (No. 0.83.0007.0)

