



# STICKGEL Monocomponent Silicone Gel

## In Cartridge

### General features

- ✓ Monocomponent silicone gel.
- ✓ Thixotropic consistency.
- ✓ Colour: transparent blue.
- ✓ Odourless.
- ✓ Without any solvent.
- ✓ 300 ml cartridge.
- ✓ Non hazardous product as per EC Directive 67/548/EEC or 1999/45/EC.
- ✓ Dielectric strength: 25 kV/mm.
- ✓ Operating temperature: -60 +200°C.
- ✓ Density: 0.97 g/l (ISO 3219).
- ✓ Self-extinguishing: HB (UL 94).
- ✓ Specific resistance: 10 G  $\Omega$ /mm.
- ✓ Volumetric loss: <0.01%.

### Applications

- ✓ Electrical connection insulation 0.6/1kV.
- ✓ Electronic board and component insulation.
- ✓ **Indicated in case of difficult access to the box and/or connection.**
- ✓ Suitable for vertical use or inverted horizon.

### Advantages

- ✓ No components to be mixed.
- ✓ Immediately ready to be used.
- ✓ Cartridge applicable on common silicone guns.
- ✓ Precise dosage which eliminates any waste.
- ✓ Reenterable.
- ✓ Removable.
- ✓ Transparent.
- ✓ Ecofriendly.
- ✓ High degree of electrical insulation.
- ✓ Protection from atmospheric elements (rain, humidity) and dust.
- ✓ Good mechanical strength.
- ✓ UV resistant.
- ✓ No expiry date.



Item  
code


Part  
No.

Volume (liters)

7901116

STICKGEL

0.3

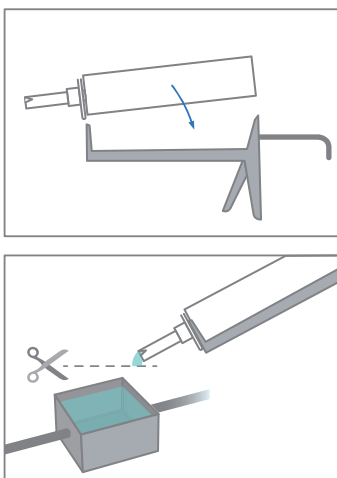

Unless otherwise stated,  
all dimensions are in millimeters.