


4013288179104

1430 Kraftform Micro ESD adjustable torque screwdrivers with quick-release chuck, 0,02 - 0,11 Nm

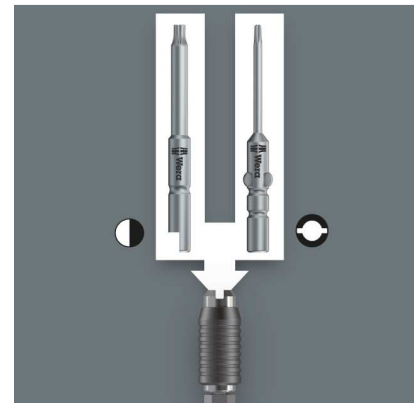

EAN:	4013288179104	Code:	05074804001
Type:	1430 ESD		
Size:	1431 ESDx0,05-0,11		

Torque screwdriver with adjustable torque from 5,0 bis 11,0 cNm (accuracy +- 10%) – Torque recommended by leading smart-phone manufacturers. Compact handle/interchangeable blade system for torque-controlled precision screwdriving jobs. The Kraftform Micro ESD torque screwdriver is ideal for the torque-controlled tightening of screws on components subject to damage from electrostatic energy. Designed to securely hold bits with 4 mm halfmoon drive (Wera Series 9) and bits with 4 mm HIOS drive (Wera Series 21). Tamperproof. Distinctly audible and noticeable excess load signal when the pre-set value is exceeded. Unlimited torque for manual loosening jobs. Electrical surface resistance of $< 10^9$ Ohm so as to securely protect components against electrostatic energy. Manufactured as per DIN EN 61340-5-1. Unique bit-holding system for rapid bit exchange. Kraftform Micro handle with spinning cap and fast-turning zone for rapid work. This makes time-consuming grip adjustments no longer necessary. The power zone with integrated soft zones ensures high torque transfer for loosening or tightening screws. The precision zone directly above the blade facilitates a correct rotation angle for fine adjustment jobs. Rapid bit attachment: Simply insert the bit in the chuck and the automatic locking mechanism ensures a secure fit. To change the bit, just push the sleeve forwards and remove the bit.