

## T 11/1 CLASSIC

Low weight, high suction power, very robust: Our dry vacuum cleaner T 11/1 Classic combines decisive criteria of professional users in an attractively priced, compact vacuum cleaner.



**Order no.** 1.527-197.0

- Outstanding price-performance ratio
- Optional HEPA 14 filter available
- Low weight

### Technical data

<b>EAN code</b>		4054278731131
<b>Power supply</b>	<b>Ph / V / Hz</b>	1 / 220 - 240 / 50 - 60
<b>Vacuum</b>	<b>mbar / kPa</b>	235 / 23.5
<b>Air flow</b>	<b>l/s</b>	40
<b>Nominal power</b>	<b>W</b>	850
<b>Container capacity</b>	<b>l</b>	11
<b>Container material</b>		Plastic
<b>Standard nominal width</b>		ID 35
<b>Cable length</b>	<b>m</b>	7.5
<b>Sound pressure level</b>	<b>dB(A)</b>	61
<b>Colour</b>		anthracite
<b>Weight without accessories</b>	<b>kg</b>	3.9
<b>Weight incl. packaging</b>	<b>kg</b>	5.9
<b>Dimensions (L × W × H)</b>	<b>mm</b>	385 × 285 × 385

### Equipment

<b>Container material</b>		Plastic
<b>Cable hook</b>		■
<b>Integrated accessory storage</b>		■
<b>Suction hose length</b>	<b>m</b>	2
<b>Bend</b>		Plastic
<b>Quantity of suction tubes</b>	<b>Piece(s)</b>	3
<b>Suction tubes length</b>	<b>mm</b>	350
<b>Suction tubes material</b>		Plastic
<b>Switchable floor nozzle</b>		■
<b>Quantity of filter bags</b>	<b>Piece(s)</b>	1
<b>Filter bag material</b>		Fleece
<b>Motor protection filters</b>		■
<b>Permanent filter basket</b>		Fleece

■ Included in the scope of supply.




## Low weight

- Effortless, also one-handed transport over ledges and steps.
- Lower weight with identical container volume compared to competitor models.
- Designed for long periods of fatigue-free use.



## Very low operating noise of only 61 dB(A)

- Ideal for working in noise-sensitive areas and at night.
- Low operating noise protects the user.

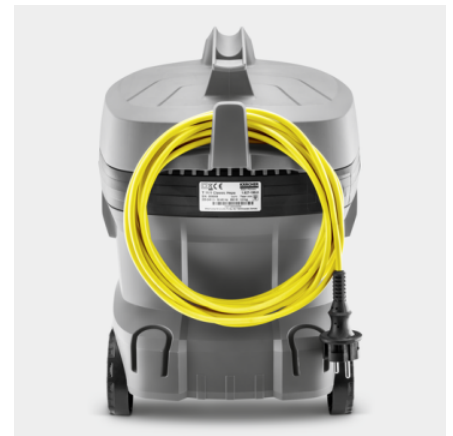

## Cable hook

- The power cable is always stored safely for transport.
- Practical cable storage.

## ACCESSORIES FOR T 11/1 CLASSIC



### 1.527-197.0



		Order no.	Description	
<b>FILTER T/ NT</b>				
<b>Main filter baskets</b>				
Permanent main filter basket, T 7/1, T 8/1, T 11/1, ProT 200	1	2.889-099.0	Robust and durable: permanent main filter basket made of non-woven material. The sustainable filter basket can be washed by hand at 30 °C and reused. Content: 1 piece.	■
<b>Exhaust air filter</b>				
Motor protection filter, 1 Piece(s), T 9/1 Bp, T 7, T 8, T 10, T 11, T 12, T 15	2	6.414-022.0	Motor protection filter, removable fleece, which can be replaced when heavily soiled.	■
<b>HEPA Filter</b>				
HEPA-14 kit for T 11/1 Classic	3	2.889-310.0	HEPA 14 filter set, comprising highly effective HEPA 14 filter, as well as the compatible main filter basket.	□
<b>BENDS</b>				
<b>Bend, plastic</b>				
Bend, T, DN 35, plastic, Clip Classic at hose end, cone at accessory end	4	2.840-040.0	DN 35 plastic bend for Classic dry vacuum cleaners. Comes with a Clip Classic connection at the hose end and a cone connection at the accessory end.	■
<b>SUCTION NOZZLES</b>				
<b>Floor nozzles</b>				
Switchable floor nozzle, DN 35, width 270 mm, with parking hook, suitable for textile and hard surfaces	5	6.907-496.0	Switchable floor nozzle for cleaning textile and hard surfaces. Made of plastic with a width of 270 mm and nominal size of DN 35. Includes practical parking hook.	■
Parquet nozzle, DN 35, width 360 mm, with parking hook, suitable for parquet floors and hard surfaces	6	2.889-196.0	Gentle cleaning of parquet floors, delicate wooden floors and other hard surfaces: plastic parquet nozzle with width of 360 mm and nominal size of DN 35. Includes practical parking hook.	□
Floor nozzle, DN 35, width 290 mm, with parking hook, suitable for textile and hard surfaces	7	2.889-360.0	High-quality plastic floor nozzle in nominal size of DN 35 for cleaning textile and hard floors. With a practical parking hook. Width: 290 mm.	□
<b>Suction brushes</b>				
Suction brush DN 35	8	2.889-221.0	Suction brush DN 35 with horsehair natural bristles.	□
<b>Turbo nozzles</b>				
Turbo floor nozzle with parking hook, DN 35/32, 270 mm wide	9	2.860-277.0	Plastic turbo floor nozzle in nominal size of DN 35/32 for cleaning textile and hard floors. With a practical parking hook and DN 35/32 reduction bushing, 270 mm wide.	□
<b>SUCTION TUBES</b>				
<b>Suction tubes, plastic</b>				
Suction tube plastics DN35 350mm	10	2.889-412.0	The suction tube made of high-quality plastic (DN 35 and 350 mm long) is suitable for dry vacuum cleaners from Kärcher.	■
<b>Suction tubes, stainless steel</b>				
Suction tube, 2 x, T, DN 35, 480 mm long, stainless steel, suitable for: T 7/1 Classic, T 8/1 L, T 11/1 Classic	11	2.643-464.0	The suction tube set consists of 2 suction tubes made of high-quality stainless steel (DN 35 and 480 mm long each). For Kärcher dry vacuum cleaners.	□
<b>SUCTION HOSES</b>				
<b>Suction hoses others</b>				
Suction hose, T, DN 35, length 2 m, Clip Classic, click fastener	12	2.889-100.0	The suction hose in nominal width DN 35 and with 2 m length is suitable for use with Classic dry vacuum cleaners.	■
<b>VACUUMS</b>				
<b>Nozzles</b>				
Flexible crevice nozzle	13	2.863-374.0	Flexible crevice nozzle for cleaning hard-to-reach areas in the home, basement, workshop, car, etc. with Home & Garden wet and dry vacuum cleaners and spray extraction cleaners.	□
<b>NOZZLE KITS</b>				
Nozzle kit: crevice nozzle, upholstery nozzle, suction brush, ID 35	14	2.860-116.0	Nozzle kit consisting of a crevice nozzle, upholstery nozzle and suction brush. The nozzle kit is suitable for all Kärcher dry vacuum cleaners and wet and dry vacuum cleaners in nominal width DN 35.	□

■ Included in the scope of supply. □ Available accessories.

## ACCESSORIES FOR T 11/1 CLASSIC 1.527-197.0

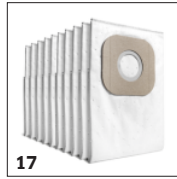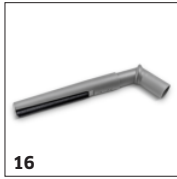

		Order no.	Description	
<b>FURTHER ACCESSORIES DRY VACUUM CLEANERS</b>				
Repair set Kaercher NW35	15	2.639-329.0	Repair kit for dry vacuum cleaner accessories in DN 35. The kit includes a threaded and clamping ring, a connecting adapter, as well as a seal.	<input type="checkbox"/>
Surface nozzle DN 35 for hard surfaces and carpeted areas	16	2.889-361.0	Innovative surface nozzle with nominal width DN 35 for dry vacuum cleaners from Kärcher. The nozzle can be used on both hard and carpeted surfaces. Working width: 180 mm.	<input type="checkbox"/>
<b>FILTER BAGS</b>				
<b>Fleece filter bags</b>				
Fleece filter bags, 10 Piece(s), T 7/1 Classic, T 8/1, T 11/1 Classic	17	6.904-084.0	Tear-resistant 3-layer fleece filter bags of dust class M, suitable for Kärcher dry vacuum cleaners. Contents: 10-pack.	<input type="checkbox"/>

■ Included in the scope of supply.     Available accessories.