



Datasheet

RS PRO 6m D25 Way M to D25 Way female Straight Through Cable


Stock number: 182-8906

EN

Our RS PRO 6m D25 male to D25 female is wire pin to pin has a beige PVC cable flex.

The connector hoods are made from beige PVC and have a strain relief on the end of the hood to support the cable and to stop the cable from splitting around the hood.

The cable flex has an outer diameter of 7mm and 28awg, the connectors have gold flash pins to help stop corrosion.

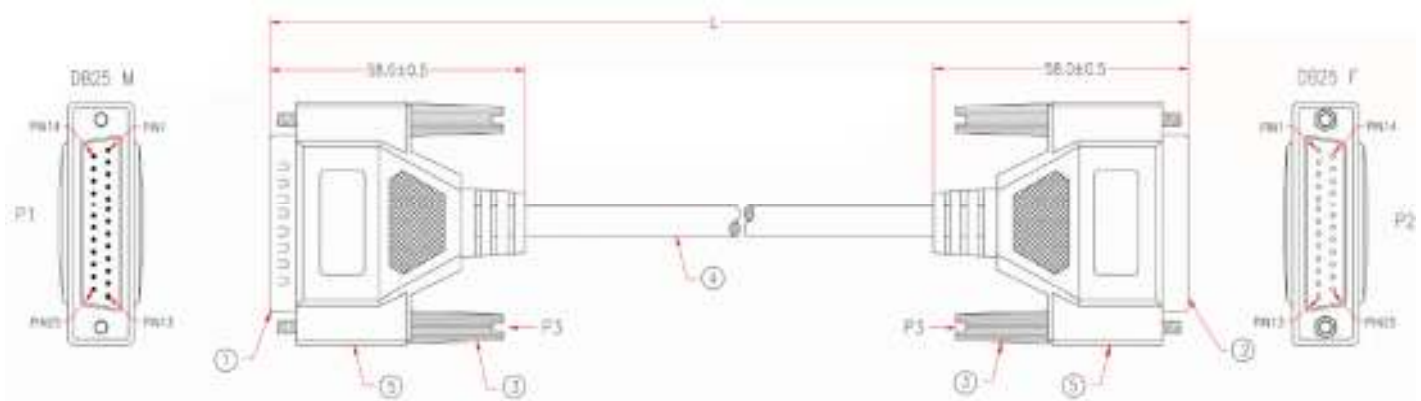

P1	P2	P1	P2
BROWN 1	1	14	14 BROWN/BLACK
RED 2	2	15	15 RED/BLACK
ORANGE 3	3	16	16 ORANGE/BLACK
PINK 4	4	17	17 PINK/BLACK
YELLOW 5	5	18	18 YELLOW/BLACK
GREEN 6	6	19	19 GREEN/BLACK
LIGHT GREEN 7	7	20	20 LIGHT GREEN/BLACK
BLUE 8	8	21	21 BLUE/BLACK
LIGHT BLUE 9	9	22	22 LIGHT BLUE/BLACK
PURPLE 10	10	23	23 PURPLE/BLACK
GREY 11	11	24	24 GREY/BLACK
WHITE 12	12	25	25 WHITE/BLACK
BLACK 13	13	SHIELD	SHIELD

5	BLACK PVC TUBE \varnothing 3.0*30mm
	ALUMINUM FOIL 33*110mm
	MOLDED PE COLOR TRANSPARENT
4	MOLDED PVC BEIGE
	NON-UL 25C 30AWG, ALUM-MYLAR FOIL SHIELDING WITH DRAIN WIRE, OD: 7.0mm, JACKET BEIGE
3	MOLDED THUMBSCREW #4-40, LENGTH 46.5mm, BEIGE
2	DB25 FEMALE, GOLD FLASH ON CONTACTS, BLUE INSULATOR
1	DB25 MALE, GOLD FLASH ON CONTACTS, BLUE INSULATOR

RoHS / REACH / CE

rspro.com