



Datasheet

ENGLISH



EES25A series 25 watt Single Output Desktop





Features

- Operating temperature: 0°C - 40°C
- Input Voltage: 100 – 240Vac
- Output Power: 25W
- Power Consumption at no-load : 0.3W Max
- AC inlet IEC320-C14 socket
- Compact and light-weight plastic case
- Protections: short circuit/overload/ overheat
- ErP compliant
- Meets CE and UL standards
- Dimensions (LxWxH mm): 99 x 52 x 36
- Connector: P1J 2.1mm
- 2 year warranty

Part number	Voltage	Rated Current	Efficiency	Line Regulation	Load Regulation	Ripple and Noise	MTBF
770-2835	5V	4A	78%	± 2%	± 5%	120mV Max	50,000hrs min. MIL-HDBK – 217F (25°C)
770-2839	7.5V	2.8A	79%				
770-2848	9V	2.5A	80%				
770-2841	12V	2A	81%				
770-2845	15V	1.67A	81%				
770-2854	18V	1.38A	81%				
770-2857	24V	1.04A	82%				
770-2851	28V	0.89A	82%				

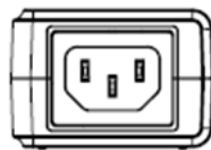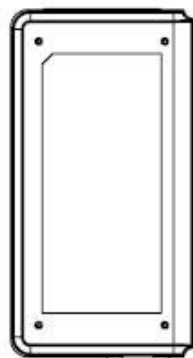

OD4.0
Safety Marking

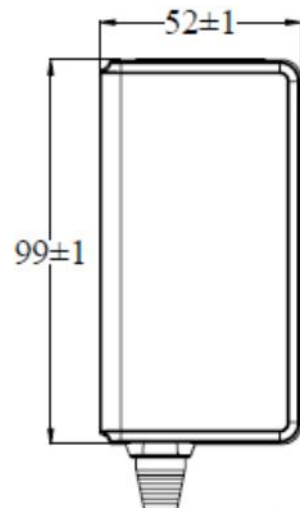 

5V to 12V
cord is
16AWG .
15V to 28V
is 18 AWG

1230±30

15±1
28±0.5
70±10

11±0.5

