




LED Floodlight 24V-36V DC 50W 7000lm 5700K

Article number: 145391

BAI LED Floodlight Low Voltage 50W 5700K 7000lm 24V-28V-36V DC IP65 IK08 Alu housing black 120° 1.4m H05RN-F cable LED Floodlight

The Floodlight is also called a spotlight or construction lamp. The Led version consumes little power and lasts a long time so that they are more durable than the traditional predecessors. Can be mounted on both wall and ceiling. The housing is made of cast aluminum. As the name implies, the Low Voltage series is designed for low voltage applications (24V-36V). Comes with 140cm connection cable. Suitable for ambient temperatures from -20°C to +50°C. Consult specifications and warranty for installation.

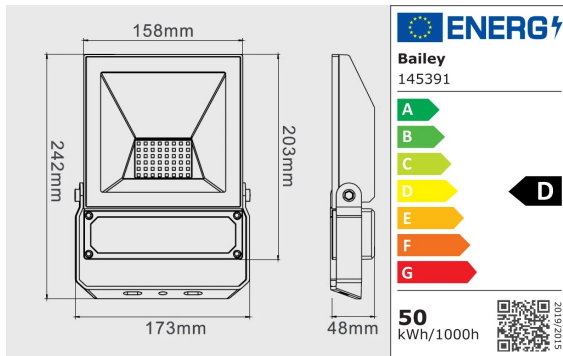

General ETIM properties

| | |
|---------------|--|
| ETIM group | Luminaires |
| ETIM class | Downlight/spot/floodlight |
| Name | LED Floodlight 24V-36V DC 50W 7000lm 5700K |
| Brand | Bailey |
| Productseries | LED Floodlight LV |
| Producttype | Low voltage |

ETIM specifications

| | |
|---|------------------------------|
| Max. system power [W] | 50 |
| Colour temperature [K] | 5700 - 5700 |
| Nominal voltage [V] | 12 - 36 |
| With movement sensor | No |
| Lamp holder | None |
| Suitable for surface mounting | Yes |
| Suitable for built-in mounting | No |
| Suitable for wall mounting | Yes |
| Suitable for suspended mounting | No |
| Suitable for ceiling mounting | Yes |
| Suitable for traverse mounting | No |
| Suitable for pedestal/floor mounting | Yes |
| Suitable for light-track mounting | No |
| Suitable for clamp-mounting | No |
| Suitable for low voltage cable system | No |
| Adjustability | Rotatable |
| With light sensor | No |
| Lamp type | LED not exchangeable |
| With light source | Yes |
| Suitable for number of light sources | 1 |
| Housing material | Aluminium |
| Surface protection | Powder coating |
| Housing colour | Black |
| Material cover | Glass transparent |
| Surface brushed | No |
| Voltage type | DC |
| Type of control gear | Low-loss ballast compensated |
| With control gear | Yes |
| Exchangeable control gear | No |
| Dimming 0-10 V | No |
| Dimming 1-10 V | No |
| Dimming DALI-2 | No |
| Dimming DALI | No |
| Dimming DMX | No |
| Dimming DSI | No |
| Dimming potentiometer (integrated) | No |
| Dimming LineSwitch | No |
| Dimming manufacturer's proprietary system | No |
| Dimming mains voltage modulation | No |
| Dimming phase cut-off (trailing edge) | No |
| Dimming phase cut-on (leading edge) | No |
| Dimming programmable | No |

| | |
|--|---------------------------|
| Dimming RF | No |
| Dimming Touch and Dim | No |
| Dimming Zigbee | No |
| Dimming with push-button | No |
| Reflector | Matt |
| Light distributor | Reflector |
| Light distribution | Symmetric |
| Beam angle | > 80° - Extreme wide beam |
| Light outlet | Direct |
| Colour rendering index CRI | 70-79 |
| Rated lifetime L70/B50 at 25 °C [h] | 30000 |
| Degree of protection (NEMA) | Other |
| Impact strength | IK08 |
| Protection class according to IEC 61140 | III |
| Rated ambient temperature according to IEC 62722-2-1 [°C] | -20 - 50 |
| Suitable for lamp power [W] | 50 - 50 |
| Colour of light | White |
| Emergency power supply system | None |
| Constant light output (CLO) | No |
| Colour of light adjustable | No |
| Luminous flux adjustable | No |
| Beam angle adjustable | No |
| Width [mm] | 48 |
| Height/depth [mm] | 242 |
| Length [mm] | 173 |
| Conductor cross section [mm²] | 1 |
| Connection type | Free conductor end |
| Power factor | 0.9 |
| Filament test according to IEC 60695-2-11 | None |
| Photobiological safety according to EN 62471 | RG1 |
| Dimmable | No |
| Luminaire with limited surface temperature, sign "D" according to EN 60598-2-24 | Yes |
| Covering of the luminaire with thermally insulating material possible | Yes |
| Number of poles | 2 |
| Suitable for workplace according to EN 12464-1 | Yes |
| Nominal current [mA] | 1150 - 1150 |
| Energy efficiency class of the light source according to EU regulation 2019/2015 | D |
| Compatible with Apple HomeKit | No |
| Colour consistency (McAdam ellipse) | SDCM6 |
| Dimming Sine Wave Reduction | No |
| Compatible with Google Assistant | No |

| | |
|---|-------------|
| Compatible with Amazon Alexa | No |
| With presence detector | No |
| IFTTT support available | No |
| Containing product according to 2019/2020/EU | No |
| Degree of protection (IP), rear side | Other |
| Degree of protection (IP), front side | IP65 |
| Operation by Bluetooth | No |
| Total harmonic distortion (THD) [%] | 20 |
| Rated luminous flux according to IEC 62722-2-1 [lm] | 7000 - 7000 |
| Luminaire efficacy [lm/W] | 140 - 140 |
| Compatible with Casambi | No |
| UK Building Regs Part B fire rated - 30 minutes | No |
| UK Building Regs Part B fire rated - 60 minutes | No |
| UK Building Regs Part B fire rated - 90 minutes | No |

Complementary articles



92100032104

Connector TH400 Tee 2-way Tube
3P