


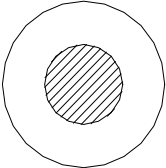

Datasheet

Product Name:	UL1213 20AWG
Product Discription:	UL1213 20AWG
Specification No.:	
Customer's Name:	

Description					Construction				
Rated Voltage:	Not specified				Conductor	Stranded Sliver plated copper			
Rated Temperature:	105°C, 60 °C Oil				Size(AWG)	20			
Reference Standard:	UL758				Construction(±0.008mm)	19/0.203			
Cross Section					Stranded Dia.(mm)Ref.	1.015			
					Insulation Material	PTFE			
					Insulation Color	ANY COLOR			
					Ave Thickness(mm)	0.25			
					Insulation Dia.(±0.09mm)	1.47			
Marking					Remark:				
No marking on the cable jacket, have UL label on the Reel.					9108465 Yellow 9108478 Orange				
					9108469 Brown				
Applications					Characteristics				Customer Approve
Internal wiring where not subjected to mechanical abuse, Oil Resistant 60 deg C.					Test Item	Standard Value			Seal & Stamp
					Test Material	PTFE(ROHS)			
					Insulation resistance(20°C MΩ*m)	1000			
					Vol. Tesr(AC.V.60S) (V)	2000			
Flammability Test	Horizontal flame								
Max.DC Resistance(20°C Ω/km)	30.1(MAX)								
Revisions					Signature: Date:				
Version	Description	Drawn by	Approved by	Date					
0	New document issue	Danniel	Jason	14/12/2015					