

Contact insert - HC-HS 6-EBUS - 1773132

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)

HEAVYCON female insert, HS6 series, 6-pos., screw connection



Key commercial data

Packing unit	10 pc
GTIN	 4 017918 037642
Weight per Piece (excluding packing)	103.12 g
Custom tariff number	85366990
Country of origin	Germany

Technical data

General

Note	For housing HC-B16
Connection method	Screw connection
Tightening torque	1.2 Nm
Pollution degree	3
Surge voltage category	III
Constructional and testing regulations	DIN VDE 0627/86
	DIN VDE 0110/02.79
	DIN VDE 0110-1/04.97
	IEC 60664-1, DIN IEC 60512
Number of positions	6+PE
Insertion/withdrawal cycles	≥ 500
Type	B16
Connection in acc. with standard	IEC / EN
Conductor cross section	0.5 mm ² ... 6 mm ²
Connection cross section AWG	20 ... 10
Stripping length of the individual wire	10 mm
Assembly instructions	Connectors may be operated only when there is no load/voltage.

Contact insert - HC-HS 6-EBUS - 1773132

Technical data

Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C (including heating up of contacts)
---------------------------------	--

Material data

Inflammability class according to UL 94	V0
Contact material	Copper alloy
Contact surface material	Ag
Contact carrier material	PA

Electrical characteristics

Rated voltage (III/3)	500 V
Rated surge voltage	6 kV
Rated current	35 A

Classifications

eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	27440209

ETIM

ETIM 2.0	EC000438
ETIM 3.0	EC000438
ETIM 4.0	EC000438
ETIM 5.0	EC000438

UNSPSC

UNSPSC 6.01	30211923
UNSPSC 7.0901	39121522
UNSPSC 11	39121522
UNSPSC 12.01	39121522
UNSPSC 13.2	39121522

Approvals

Approvals

Contact insert - HC-HS 6-EBUS - 1773132

Approvals

Approvals

CSA / UL Recognized / GOST

Ex Approvals

Approvals submitted

Approval details

CSA 	
mm ² /AWG/kcmil	20-10
Nominal current I _N	35 A
Nominal voltage U _N	600 V


UL Recognized 	
mm ² /AWG/kcmil	10
Nominal current I _N	35 A
Nominal voltage U _N	600 V

GOST 	
--	--

Drawings


Contact insert - HC-HS 6-EBUS - 1773132

Schematic diagram

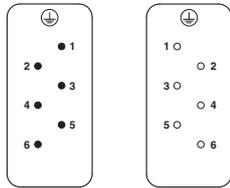


Connector pin assignment, connection side

Diagram

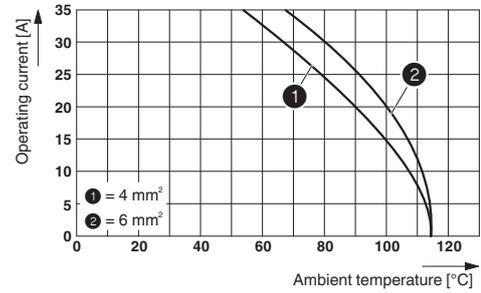


Derating diagram: HC-HS...S series

Dimensioned drawing

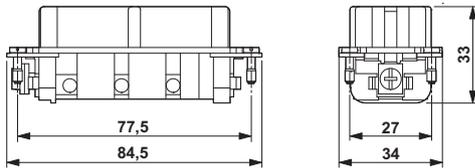

Female insert

Dimensioned drawing

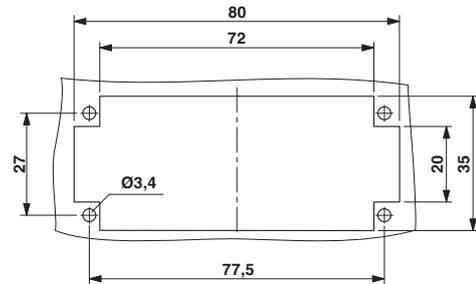

Panel cutout