


92 series comms boxes

TAKACHI

Product overview

Low profile and deep profile plastic housings with removable end panels. Ideal for communication equipment such as Wi-Fi routers.

- Stylishly designed ABS plastic case with double detachable panels
- Flame resistant ABS (UL94-V0), 30 sizes, available in off-white and dark grey
- Equipped with built-in bosses for PCB mounting
- Suitable for WiFi access points, measuring equipment, control and communication applications
- 92 series has been designed to meet the requirements of IP40

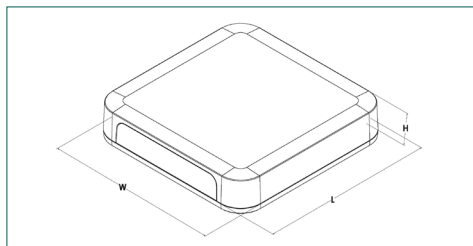

SPECIFICATION

Materials	Base, top and panel UL94-V0 ABS
Protection class	92 series has been designed to meet the requirements of IP40
Operating temperature	-10°C to +60°C
Standard colours	Dark grey Off-white
Standard unit includes	Base, top and panel 4x self tapping screw 4x rubber feet

DARK GREY	WHITE	LENGTH	WIDTH	HEIGHT
PF15-3-10D	PF15-3-10W	100mm	150mm	30mm
PF15-5-10D	PF15-5-10W	100mm	150mm	45mm
PF15-3-15D	PF15-3-15W	150mm	150mm	30mm
PF15-5-15D	PF15-5-15W	150mm	150mm	45mm
PF20-4-13D	PF20-4-13W	135mm	200mm	40mm
PF20-6-13D	PF20-6-13W	135mm	200mm	60mm
PF20-4-20D	PF20-4-20W	200mm	200mm	40mm
PF20-6-20D	PF20-6-20W	200mm	200mm	60mm
PF10-2-7D	PF10-2-7W	67mm	100mm	22.5mm
PF10-2-10D	PF10-2-10W	100mm	100mm	22.5mm
PF10-2-15D	PF10-2-15W	150mm	100mm	22.5mm
PF10-4-7D	PF10-4-7W	67mm	100mm	35mm
PF10-4-10D	PF10-4-10W	100mm	100mm	35mm
PF10-4-15D	PF10-4-15W	150mm	100mm	35mm
PF10-6-15D	PF10-6-15W	150mm	100mm	55mm
PF13-3-9D	PF13-3-9W	85mm	125mm	25mm
PF13-3-13D	PF13-3-13W	125mm	125mm	25mm
PF13-3-19D	PF13-3-19W	190mm	125mm	25mm
PF13-4-9D	PF13-4-9W	85mm	125mm	40mm
PF13-4-13D	PF13-4-13W	125mm	125mm	40mm
PF13-4-19D	PF13-4-19W	190mm	125mm	40mm
PF13-6-19D	PF13-6-19W	190mm	125mm	60mm
PF18-4-12D	PF18-4-12W	120mm	175mm	35mm
PF18-4-18D	PF18-4-18W	175mm	175mm	35mm
PF18-5-12D	PF18-5-12W	120mm	175mm	50mm
PF18-5-18D	PF18-5-18W	175mm	175mm	50mm
PF24-4-17D	PF24-4-17W	165mm	240mm	42.5mm
PF24-4-24D	PF24-4-24W	240mm	240mm	42.5mm
PF24-6-17D	PF24-6-17W	165mm	240mm	60mm
PF24-6-24D	PF24-6-24W	240mm	240mm	60mm

268
HANDHELD CASES

292
UNIVERSAL ENCLOSURES

318
HEAVY DUTY AND ELECTRICAL ENCLOSURES

342
DESKTOP AND INSTRUMENT CASES

348
DEVELOPMENT BOARD ENCLOSURES

367
ROOM SENSOR ENCLOSURES

370
CUSTOM SIZED ENCLOSURES

DARK GREY	WHITE	LENGTH	WIDTH	HEIGHT	
PF28-5-20D	PF28-5-20W	200mm	280mm	45mm	NEW
PF28-7-20D	PF28-7-20W	200mm	280mm	65mm	NEW
PF28-9-20D	PF28-9-20W	200mm	280mm	90mm	NEW
PF32-5-23D	PF32-5-23W	225mm	320mm	45mm	NEW
PF32-7-23D	PF32-7-23W	225mm	320mm	65mm	NEW
PF32-10-23D	PF32-10-23W	225mm	320mm	90mm	NEW

KEY FEATURES

Flame resistant ABS | 36 sizes available | Removable end panels



PLASTIC ENCLOSURES