


OPEN HOSE REELS FOR COMPRESSED AIR / STEEL

DGO series - Large - Rubber hose



Part number	Length (m)	Flow rate (l/min)	Max. operating pressure (bar)	Net weight (Kg)	Male thread	Female thread	Profile
DGO 1025ES	25.00	500.00	12.00	23		G3/8	EUROPEAN
DGO 1320ES	20.00	1000.00	12.00	22,5	G1/2		EUROPEAN

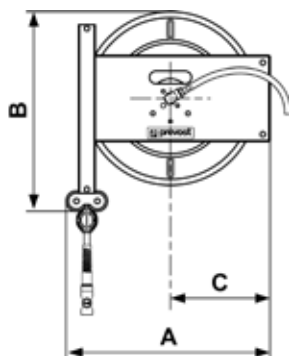

Part number	Dim. A (mm)	Dim. B (mm)	Dim. C (mm)	Ø int/ext (mm)
DGO 1025ES	485.00	475.00	237.00	10.00 / 17.00
DGO 1320ES	485.00	475.00	237.00	13.00 / 20.00