


DX2053



Multifunction display for monitoring analogue standard signals

DISPLAY/AX460/ANALOG/DC

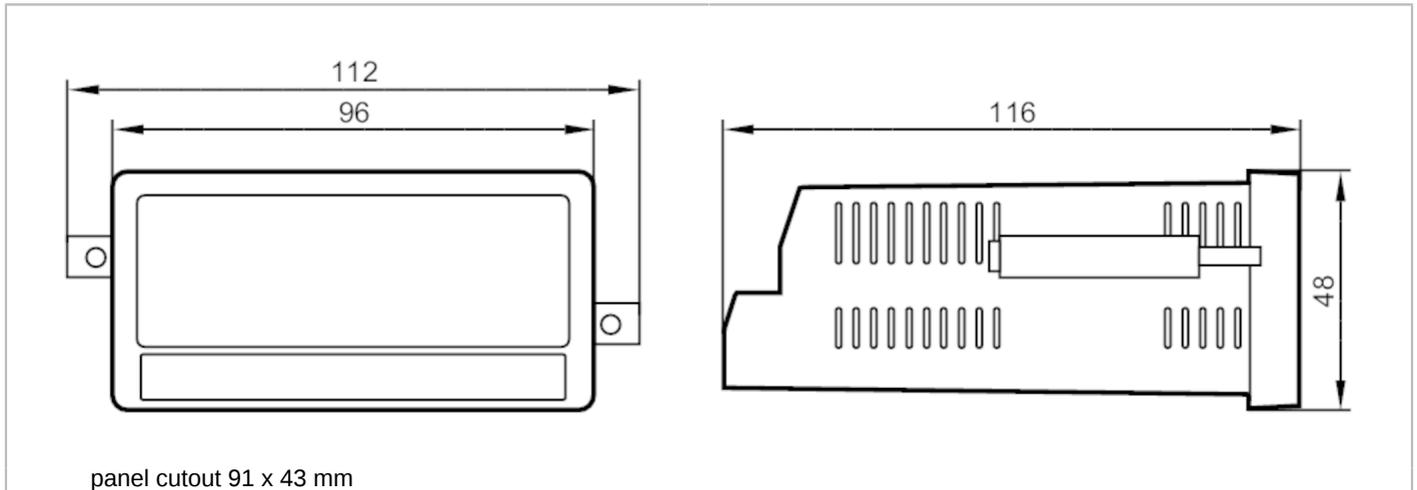

Product characteristics	
Housing	housing for panel mounting
Dimensions [mm]	48 x 112 x 116
Application	
Application	displaying and monitoring analogue signals; e.g. pressure sensors, temperature sensors or flow sensors
Electrical data	
Operating voltage [V]	18...30 DC
Current consumption [mA]	100
Inputs / outputs	
Number of inputs and outputs	Number of analogue inputs: 2; Number of digital outputs: 4; Number of analogue outputs: 1
Inputs	
Number of analogue inputs	2; (Spannungs- oder Stromeingang)
Analogue input (current) [mA]	0...20
Analogue input (voltage) [V]	-10...10
Resolution of analogue input	16 bit
Precision analogue input [%]	0,1
Outputs	
Number of digital outputs	4
Max. current load per output [mA]	200
Number of analogue outputs	1
Analogue current output [mA]	0...20
Max. load [Ω]	270
Analogue voltage output [V]	-10...10
Precision analogue output [%]	0,1
Overload protection	yes
Resolution of analogue output	16 bit

