


Tapered roller bearings, single row

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	T	dynamic C	static C0	Reference speed		* SKF Explorer bearing
mm			kN		r/min		-
29	50,292	14,224	26	32,5	10000	14000	L 45449/410/Q

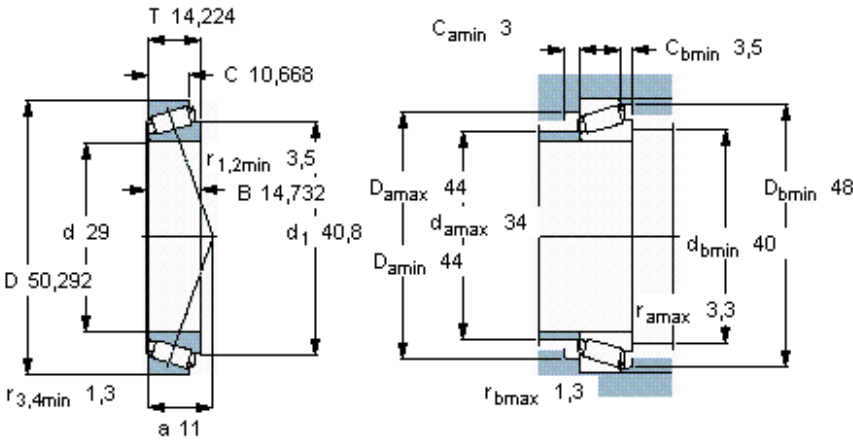

Calculation factors
e 0,37
Y 1,6
Y₀ 0,9