


ZM150

Precision locknut

Precision locknut ZM, accessory ZM..

Technical information

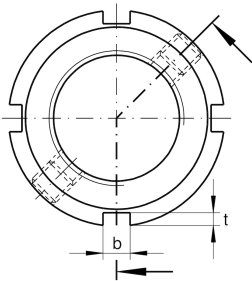

Main Dimensions & Performance Data

d	M150X2	Thread
D	195 mm	Outside diameter
h	26 mm	Height
M _A	38 Nm	Mounting torque set screw
F _{aB}	750,000 N	Breaking load, axial
M _L	900 Nm	Breakawag
M _{AL}	650 Nm	Mounting torque reference
M _M	188 kg*cm2	Mass moment of inertia

≈m 2.24 kg Weight

Dimensions

d ₁	171 mm	Plant diameter outside
t	6 mm	Hight retaining slot
b	14 mm	Width retaining slot
c	13 mm	Distance bore
m	M12	Threaded - threaded pin