




## NT 50/1 Tact Te H

Licensed for asbestos abatement and many other applications: 50/1 Tact Te H wet and dry vacuum cleaner with 50-litre container for vacuuming hazardous dusts in dust class H.



2 SING PICTURE: M:\print\  
nt\_50\_1\_Tact\_Te\_H\_asbest\_abate-  
ment\_sanding\_floor\_app\_1\_  
CI15502x502\_169634.tif

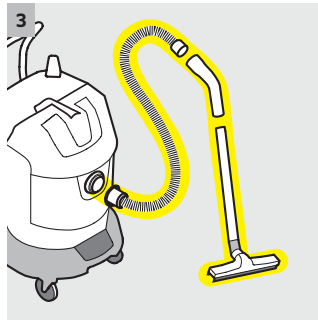

### 1 Filtration system with H filter and Tact filter cleaning system

- Sucks less dangerous dust directly into the container. Filtration efficiency: 99.995 per cent.
- The greatest possible health protection without sacrificing suction power or filter endurance.

### 2 Fulfils testing requirements for dust class H, with additional test for “Asbestos” in accordance with TRGS 519

- In Germany, only safety vacuum cleaners with this licence are allowed to be used to vacuum dust that contains asbestos.

### 3 Complete antistatic system with conductive accessories

- Users are effectively protected against electric shocks and electrostatic charging.

### 4 Power outlet with automatic on/off switch

- Te versions are equipped with power outlet, automatic on/off switch and antistatic preparation.



## NT 50/1 Tact Te H

- Complete antistatic system, incl. conductive accessories
- Socket with automatic start-up for electric tools
- Licensed for asbestos abatement

### Technical data

<b>Order no.</b>	1.148-437.0	
<b>EAN code</b>	4054278061405	
<b>Supply voltage</b>	<b>Ph / V / Hz</b>	1 / 220 - 240 / 50 - 60
<b>Air flow</b>	<b>l/s</b>	74
<b>Vacuum</b>	<b>mbar / kPa</b>	273 / 27.3
<b>Container content</b>	<b>l</b>	50
<b>Rated input power</b>	<b>W</b>	1380
<b>Standard nominal width</b>	DN 35	
<b>Rubber power cable length</b>	<b>m</b>	7.5
<b>Sound pressure level</b>	<b>dB(A)</b>	69
<b>Weight</b>	<b>kg</b>	19.6
<b>Dimensions (L x W x H)</b>	<b>mm</b>	640 × 370 × 1045


### Equipment

<b>Safety filter bag</b>	<b>piece(s)</b>	1	<b>Sturdy bumper</b>	■
<b>Suction hose</b>	<b>m</b>	4 / with bend (electrically conductive)	<b>Push handle</b>	■
<b>Suction tube</b>	<b>piece(s) × m</b>	2 × 0.55 / Stainless steel	<b>Protection class</b>	I
<b>Filter bag</b>	Fleece		<b>Stop swivel castor</b>	■
<b>Wet/dry floor nozzle</b>	<b>mm</b>	360	<b>Filter cleaning</b>	Tact Filter Clean
<b>Crevice nozzle</b>	■		<b>Dust class</b>	H
<b>Power tool connection adapter</b>	■		<b>PE plastic bag for dust-free disposal</b>	<b>piece(s)</b> 1
<b>Drain hose</b>	■			
<b>Automatic switch-on/off for electric devices</b>	■			
<b>Anti-static system</b>	■			
<b>Flat pleated filter</b>		PTFE HEPA		

■ Included in the scope of supply.

# NT 50/1 TACT TE H

## 1.148-437.0

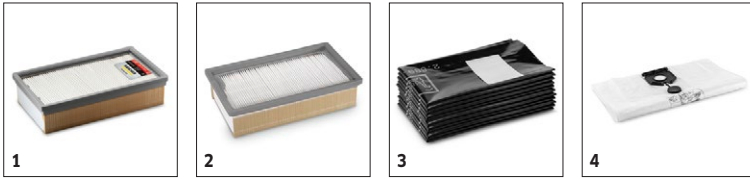

		Order no.	Quantity				Price	Description	
<b>Flat pleated filter HEPA, dust class H</b>									
Safety/HEPA flat pleated filter	1	6.907-671.0	1 piece(s)					Safety/HEPA flat pleated filter made from PES/PTFE fibre material with a red label. Certified for dust class H. For vacuuming hazardous dusts, coarse dirt and liquids.	<input checked="" type="checkbox"/>
HEPA-14 flat pleated filter	2	6.904-242.0	1 piece(s)					HEPA-14 (H14) flat pleated filter for Kärcher wet and dry vacuum cleaners. Suitable for vacuuming hazardous dusts, coarse dirt and liquids.	<input type="checkbox"/>
<b>Plastic sacks for dust-free disposal</b>									
Plastic bag for dust-free disposal	3	2.889-231.0	10 piece(s)					PU plastic bag for dust-free disposal. Pack of 10.	<input type="checkbox"/>
<b>Safety filter sets/bags</b>									
Safety filter bag	4	2.889-184.0	5 piece(s)					Safety filter set with dust disposal bag, for dust class H safety vacuum cleaners. Guarantees the dust-free disposal of dangerous dust.	<input type="checkbox"/>

Included in the scope of supply.
  Available accessories.

# NT 50/1 TACT TE H

## 1.148-437.0

**KÄRCHER**



		Order no.	Quantity	ID	Length	Width	Price	Description	
<b>Bend, plastic</b>									
Bend Adv, electrically conductive	1	2.889-168.0	1 piece(s)	DN 35				Ergonomic bend for the new clip system. Electrically conductive design. Particularly suited to high concentrations of fine dust.	■
Bend Adv	2	2.889-170.0	1 piece(s)	DN 35				Ergonomic bend for the new clip system.	□
DN 40 bend	3	2.889-171.0	1 piece(s)	DN 40				Bend for the new clip system in nominal size DN 40.	□
Bend, electroconductive, NW40	4	2.889-172.0	1 piece(s)	DN 40				Bend for the new clip system in nominal diameter DN 40. In electrically conductive version. Especially suitable in event of large quantity of fine dust.	□
<b>Floor nozzles</b>									
Wet and dry floor nozzle Adv	5	2.889-152.0	1 piece(s)	35		360 mm		360 mm wide wet and dry floor nozzle with easy-to-change inserts. Including brush strips and squeegees.	■
Wet/dry floor nozzle, plastic Adv, DN 40	6	2.889-153.0	1 piece(s)	40		360 mm		360 mm wide wet and dry floor nozzle with easy-to-change inserts, squeegees.	□
Wet/Dry floor nozzle standard	7	2.889-173.0	1 piece(s)	35		300 mm		300 millimetre width, anthracite coloured wet/dry floor nozzle, NW 35. With easy-to-change inserts. Incl. brush strips and squeegees.	□
Wet/Dry floor nozzle standard DN40	8	2.889-174.0	1 piece(s)	40		360 mm		Standard floor nozzle, anthracite, in nominal diameter 40, with brush strips and squeegees. Suitable for all wet and dry applications.	□
<b>Crevice nozzles</b>									
Crevice nozzle DN 35 wet and dry vacuum cleaners 225 mm	9	2.889-159.0	1 piece(s)	35	225 mm			Crevice nozzle with nominal width DN 35 for Kärcher wet and dry vacuum cleaners. Length 225 mm.	■
Crevice nozzle NT Tact DN 40	10	2.889-160.0	1 piece(s)	40 mm	225 mm			Crevice nozzle ID 40, for new Tact range.	□
<b>Suction tubes, stainless steel</b>									
Set suction tube stainless steel NW35 55	11	2.889-192.0	2 piece(s)	35	550 mm			Stainless steel suction tube set (2 × 0.55 m)	■
Suction tube	12	6.902-081.0	1 piece(s)	40	500 mm			Stainless steel suction tube (DN 40, 0.5 m) only suitable for NT vacuum cleaners.	□
Set suction tube stainless steel NW40 55	13	2.889-194.0	2 piece(s)	40	550 mm			Stainless steel suction tube set (2 × 0.55 m)	□
<b>Car cleaning nozzles</b>									
Car nozzle	14	6.906-108.0	1 piece(s)	DN 35		90 mm		Flat angled, convenient, plastic, DN 35 car cleaning nozzle designed for all Kärcher wet and dry vacuum cleaners with bends. Working width: Approx. 90 mm.	□
<b>Rubber suction tools, nose 45°</b>									
Rubber suction tool, nose 45°	15	6.902-104.0	1 piece(s)	35 mm	220 mm			45° rubber suction nozzle (DN 35), oil-resistant and suitable for vacuuming machines. Only for NT vacuum cleaners.	□
	16	6.902-105.0	1 piece(s)	40 mm	220 mm			45° rubber suction nozzle (DN 40), oil-resistant and suitable for vacuuming machines. Only for NT vacuum cleaners.	□
<b>Suction tubes, metal</b>									
Suction tube set, chrome-plated, NW 35 550 mm	17	2.889-191.0	2 piece(s)	35	550 mm			Suction tube set, metal-chrome-plated, NW 35, 2-part, each 0.55 millimetres.	□

■ Included in the scope of supply. □ Available accessories.

# NT 50/1 TACT TE H 1.148-437.0

**KÄRCHER**




		Order no.	Quantity	ID	Length		Price	Description
<b>Complete suction hoses (clip system)</b>								
Electrically conductive suction hose	1	2.889-137.0	1 piece(s)	DN 35	4 m			4 m suction hose with new bayonet and clip fastener. Electrically conductive. <input checked="" type="checkbox"/>
Suction hose DN 35 4 m	2	2.889-135.0	1 piece(s)	DN 35	4 m			4 m suction hose with new bayonet and clip fastener. <input type="checkbox"/>
Electrically conductive suction hose	3	2.889-136.0	1 piece(s)	DN 35	2.5 m			Electrically conductive suction hose with new bayonet and clip fastener. Length: 2.5 m. <input type="checkbox"/>
Suction hose DN 40, length 4 m	4	2.889-138.0	1 piece(s)	DN 40	4 m			4 m long suction hose with new bayonet and clip fastener. <input type="checkbox"/>
Suction hose	5	2.889-139.0	1 piece(s)	DN 40	2.5 m			Suction hose with new bayonet and clip fastener. Length: 2.5 m. <input type="checkbox"/>
Suction hose, oil-resistant	6	2.889-140.0	1 piece(s)	DN 40	4 m			Oil-resistant suction hose with new bayonet and clip fastener. Length: 4 m. <input type="checkbox"/>
Electrically conductive suction hose	7	2.889-141.0	1 piece(s)	DN 40	4 m			4 m long, electrically conductive suction hose with new bayonet and clip fastener. <input type="checkbox"/>
	8	2.889-142.0	1 piece(s)	DN 40	2.5 m			Suction hose, electrically conductive, with new bayonet and clip fastener. 2.5 m long. <input type="checkbox"/>
<b>Repair kits</b>								
Repair kit ID 35	9	2.889-149.0	1 piece(s)	DN 35				Repair kit ID 35 for the new clip system. <input type="checkbox"/>
Repair kit ID 40	10	2.889-150.0	1 piece(s)	DN 40				Repair kit ID 40 for the new clip system. <input type="checkbox"/>
<b>Extension hoses (clip system)</b>								
Extension hose	11	2.889-145.0	1 piece(s)	DN 35	2.5 m			Extension hose for new clip system ID 35. Length: 2.5 m. <input type="checkbox"/>
	12	2.889-146.0	1 piece(s)	DN 40	2.5 m			Extension hose for new clip system ID 40. Length: 2.5 m. <input type="checkbox"/>
Extension hose DN 35 electrically conductive 2.5 m	13	2.889-343.0	1 piece(s)	DN 35	2.5 m			<input type="checkbox"/>

■ Included in the scope of supply. □ Available accessories.

# NT 50/1 TACT TE H

## 1.148-437.0

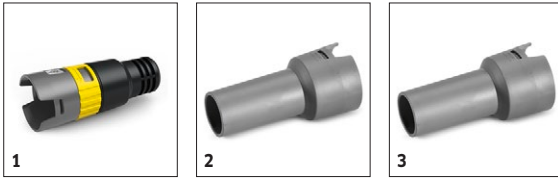

		Order no.	Quantity	ID			Price	Description	
<b>Connection adapter for power tools, clip-on, electrically conductive</b>									
Tool collar DN 35, clip-on	1	2.889-151.0	1 piece(s)	35 mm				Tool adaptor with a rubber fixture and airflow control slide for the new clip system. Suitable for all current electric tools.	■
<b>Connection adapter C ID (clip to cone), electrically conductive</b>									
Adapter clip DN 35 on cone DN 35	2	5.407-005.0						Adapter clip system DN 35 for connecting suction tubes and small nozzles to cone DN 35. Perfect for vehicle interior cleaning, even without the connection of other nozzles.	□
Adapter clip DN 40 to cone DN 40	3	5.407-006.0		DN 40				For connecting small nozzles and suction tubes with cone DN 40: Adapter clip system DN 40. Ideal for vehicle interior cleaning tasks, with no need to connect additional nozzles.	□


■ Included in the scope of supply. □ Available accessories.

# NT 50/1 TACT TE H 1.148-437.0

		Order no.	Flow rate	Length of the product	Length	Price	Description	
<b>Teleskopstangen</b>								

■ Included in the scope of supply. □ Available accessories.

# NT 50/1 TACT TE H 1.148-437.0

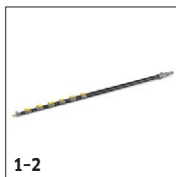



# NT 50/1 TACT TE H

## 1.148-437.0



		Order no.	Quantity	Width			Price	Description	
<b>Other accessories NT</b>									
Drilling dust nozzle	1	2.679-000.0	1 piece(s)					Drilling dust nozzle for dust-free vacuuming of boreholes. Suitable for dry and wet and dry vacuum cleaners from Kärcher.	<input type="checkbox"/>
Adapter clip new on clip old DN 35	2	2.889-312.0						Adapter for connection of hoses of the new accessory system of dry and wet and dry vacuum cleaners to bends or extension hoses of the old system. For nominal width DN 35.	<input type="checkbox"/>
Adapter connection, electroconductive	3	5.031-436.0						Electroconductive, universal adapter for connecting old NT hoses of nominal widths DN 35, 40, 50 to the new accessory system for wet and dry vacuum cleaners from Kärcher.	<input type="checkbox"/>

■ Included in the scope of supply. □ Available accessories.