
6411

Festoon lamps for cars



Areas of application

- Number plate and side position lights
- Interior lighting and reading lights

Product benefits

- OEM Quality
- Wide product range
- Reliable quality

Product features

- Original spare parts

Technical data

Electrical data


Power input	10 W
Nominal wattage	10.0 W
Nominal voltage	12.0 V
Power input tolerance	±10 %
Test voltage	13.5 V

Photometrical data

Luminous flux	100 lm ¹⁾
Luminous flux tolerance	±30 %

¹⁾ Minimum

Dimensions & weight

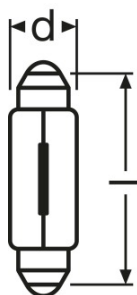

Length	41.0 mm
Diameter	11.0 mm

Lifespan

Lifespan B3	500 h
Lifespan Tc	1000 h

Additional product data

Base (standard designation)	SV8.5-8
-----------------------------	---------

Certificates & standards

ECE category	-
--------------	---

Country specific categorizations

Product datasheet

Order reference	6411 10W 12V SV
------------------------	-----------------

Country specific information

Product code	METEL code	SEG number	STK-Number	UK Org
4050300891354	OSRA6411	8328168	-	-
4050300925646	OSRA6411BLI2	8328306	-	-

Product datasheet

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4050300891354	6411	Unpacked 1	43 mm x 10 mm x 10 mm	0.00 dm ³	5.50 g
4050300891361	6411	Folding carton box 10	52 mm x 58 mm x 145 mm	0.44 dm ³	50.00 g
4008321093745	6411	Shipping carton box 50	273 mm x 65 mm x 145 mm	2.57 dm ³	315.00 g
4050300925646	6411	Blister 2	95 mm x 20 mm x 70 mm	0.13 dm ³	13.00 g
4008321140456	6411	Shipping carton box 20	137 mm x 106 mm x 103 mm	1.50 dm ³	149.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.