


# Datasheet

## Snap Mounting Outlet

RS Stock 896-2114



Dimensions: (mm)

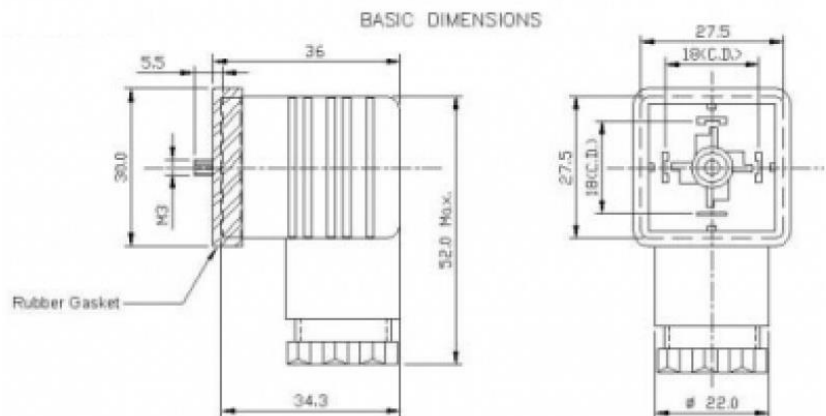

### Specifications

Connection Type:	3 Pole + Earth
Voltage:	12 VDC / 24 VDC / 48 VDC / 110 VDC / 250 VDC / 110 VAC / 250 VAC
Approvals:	NA
Standard:	NA
Mounting:	Screw Type
Type:	HD-Socket (HI-DOME) – Illuminated
Socket Type:	Type A
DC V Range:	12,24,48
Mounting:	M3 Screw
Material For Rubber Gasket:	Nitril / Silicon
Material Body:	Polycarbonate
Gland Size:	PG-9
Body Colours:	Transparent Body
Contact Resistance:	20m Ohms max
Current Carrying Parts:	Copper alloy / Tin plated
Permissible Temp. With/Without Load:	0ï¿½C to 90ï¿½C
Rating:	10A 110VAC, 230VAC
Terminals:	Screw-type
H.V Breakdown Test:	2 KV AC For 1 Minute
Insulation Resistance:	100 M Ohms min.