




**Part Number :** [731000158](#)

**Product Description :** SMB Jack, Straight, Bulkhead Receptacle, Solder Cup Contact, Brass Body, Gold (Au) Plated, Tray, 75 Ohms

**Series Number :** 73404

**Status :** Active

**Product Category :** RF / Coaxial Connectors

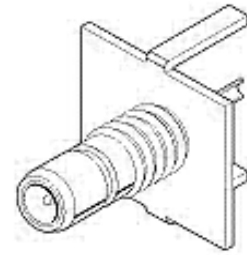

---

## Documents & Resources

### Drawings

[731000158\\_sd.pdf](#)

### 3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

### Specifications

[PS-73598-0093-001.pdf](#)

---

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Reviewed per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2025)4165-DC (25 June 2025)
EU RoHS	Not Reviewed per EU 2015/863

### [Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

### [Industry Documents](#)

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

#### Substances of Interest

- PFAS

#### EU RoHS Certificate of Compliance

#### Additional Product Compliance Information

---

## Part Details

### General

Status	Active
Category	RF / Coaxial Connectors
Series	73404
Description	SMB Jack, Straight, Bulkhead Receptacle, Solder Cup Contact, Brass Body, Gold (Au) Plated, Tray, 75 Ohms
Comments	Solder Pot
Product Name	SMB
Style	Panel
Type	Subminiature
UPC	800753686090

### Electrical

Frequency	6 GHz
Impedance	75Ω
Power / Voltage	VOLTAGE: 335 Vrms@Sea Level

### Physical

Cable Attachment	Solder
Gender	Jack
Keying to Mating Part	N/A
Net Weight	3.160/g
Orientation	Straight

Packaging Type	Tray
Panel Mount	Yes
Panel Mount Method	Bulkhead
PCB Mounting	N/A
Reverse Polar	No
Wire/Cable Type	N/A

### **Solder Process Data**

Lead-Free Process Capability	SMC&WAVE
Max-Temp	260

---

This document was generated on Aug 11, 2025