




ENGLISH

Datasheet

RS Pro Straight Heavy Duty Adjustable Tap Wrenches

RS Stock No: 444-936

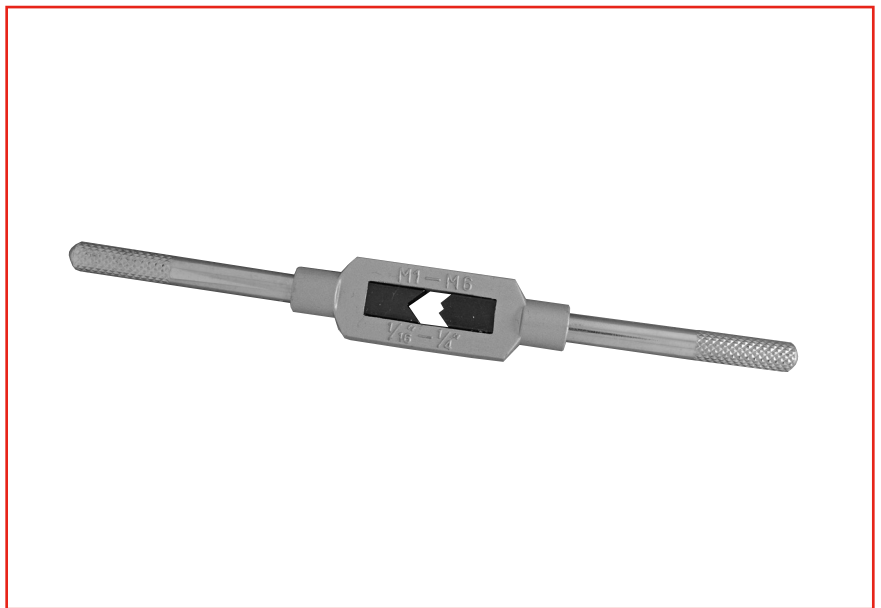

Specifications:

All steel construction

Bar type handles, chrome plated with knurled ends

Black finish steel body with hardened and tempered vee jaws

A/F Min: 2.6mm

A/F Max: 9.5mm

Overall Length: 205mm

Order Code	Manufacturers Code	Description
444-936	STW-M12	Heavy Duty Tap Wrenches



ENGLISH

Datasheet

RS Pro Straight Heavy Duty Adjustable Tap Wrenches

Tap Range:

Square Dimensions	ISO 529 Metric Coarse Full Diameter	ISO 529 Metric Coarse Relieved Shank	DIN 352 Metric Coarse	ISO 529 BSW	ISO 529 BSF	ISO 529 UNC	ISO 529 UNF	ISO 529 BA	ANSI NPT
Size mm	Size	Size	Size	Size	Size	Size	Size	Size	Size
2.5	M3	M4	M3	1/8				5	
2.8		M4.5						4	
2.9			M3.5						
3									
3.15	M4	M5		5/32					
3.3			M4						
3.5								3	
3.55	M4.5	M6							
3.8			M4.5						
4	M5			3/16	3/16			2	
4.2			M5						
4.5		M7							
4.9								0	
5	M6	M8	M6	1/4	1/4	1/4	1/4		
5.6	M7	M9							
5.9									1/16
6			M7						
6.3	M8	M10, M11		5/16, 7/16	5/16, 7/16	5/16, 7/16	5/16, 7/16		
6.8			M8						
7.1	M9	M12		1/2	1/2	1/2	1/2		
7.8			M9						
8	M10			3/8	3/8	3/8	3/8		
8.3									1/8
8.5			M10						
9		M14		9/16	9/16	9/16	9/16		
9.5			M11						