



Alphabetical   Picture   Part Number  
**SEARCH**   **SEARCH**   **SEARCH**

Go To Step Search™ Screen


**5-826925-0** -- 1 of 1 products

General **INFO**

AMPMODU

Sales **INFO**

Through Hole Headers

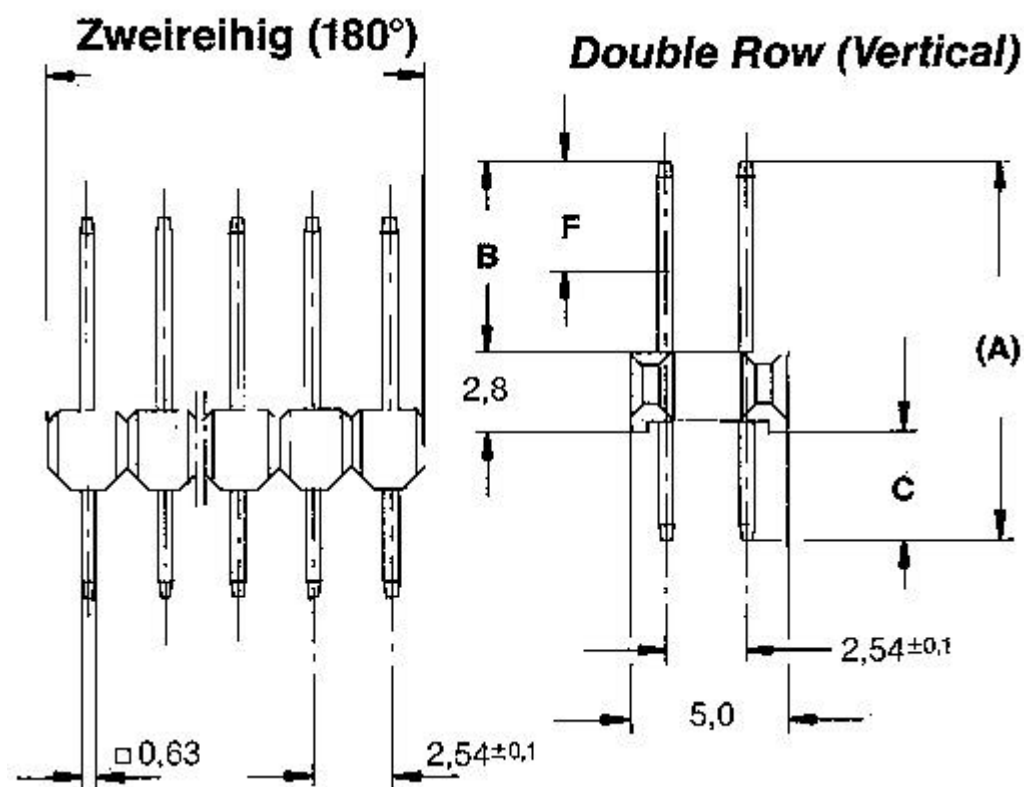

Line art represents typical product only.

<b><i>Searchable Features:</i></b>	
<b># of Rows</b>	Dual
<b># of Positions</b>	100
<b>Breakaway Header</b>	Yes
<b>Profile</b>	Standard
<b>Shrouded</b>	No
<b>PCB Mount Angle</b>	Vertical
<b>PCB Retention Feature</b>	Without
<b>Surface Mount Compatible</b>	No
<b>Contact Mating Area Plating</b>	Tin over Nickel
<b>Board Standoff</b>	Without
<b>Mounting Ears</b>	Without
<b>Panel Attachment</b>	No
<b>Mating Connector Lock</b>	Without
<b>High Temperature Housing</b>	No
<b><i>Other Properties:</i></b>	
<b>Dim. A</b>	.488 [12.40] in. [mm]
<b>Dim. B</b>	.264 [6.70] in. [mm]
<b>Dim. C</b>	.114 [2.90] in. [mm]
<b>Dim. F</b>	.217 [5.50] in. [mm]
<b>Contact Material</b>	Brass
<b>Solder Tail Plating</b>	Tin
<b>Housing Material</b>	Thermoplastic Polyester
<b>Housing Flammability Rating</b>	UL 94V-0
<b>Housing Color</b>	Green