


Geberit Mapress Stainless Steel adapter union with male thread and plain end

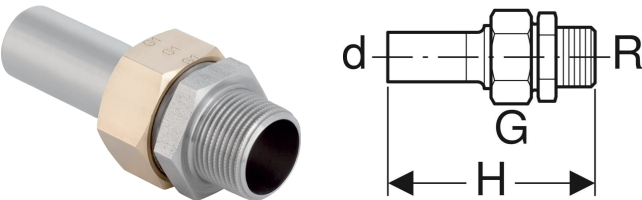

Example image

APPLICATION PURPOSES

- For cold and hot potable water
  - For cooling and heating water without antifreeze agent
  - For service water and process water
  - For treated water
  - For rainwater with a pH value  $\geq 5.5$
  - For grey and black water with a pH value  $\geq 5.5$
  - For extinguishing water (wet)
  - For extinguishing water (wet/dry, dry)
- For sprinklers (wet)
  - For chemicals and technical liquids
  - For compressed air (oil purity class 0–3)
  - For negative pressure
  - For inert gases (e.g. nitrogen)
  - For industrial gases (e.g. acetylene, shielding gases)
  - For technical building systems, industry and shipbuilding

CHARACTERISTICS

- LABS-free
- Union nut made of brass
- Flat gasket made of EPDM

TECHNICAL DATA

|                                          |                                |
|------------------------------------------|--------------------------------|
| Medium temperature with flat gasket EPDM | 0–100 °C                       |
| Product material                         | CrNiMo steel 1.4401 (EN 10088) |

| Art. no. | DN      | d, ø mm | R " | G " | H cm |
|----------|---------|---------|-----|-----|------|
| 35400    | 12 / 15 | 15      | 1/2 | 3/4 | 8.6  |
| 35402    | 15      | 18      | 1/2 | 3/4 | 8.6  |
| 35405    | 20      | 22      | 3/4 | 1   | 9.2  |

| Art. no. | DN | d <sub>ø</sub><br>mm | R<br>" | G<br>" | H<br>cm |
|----------|----|----------------------|--------|--------|---------|
| 35407    | 25 | 28                   | 1      | 1 1/4  | 10.1    |
| 35408    | 32 | 35                   | 1 1/4  | 1 1/2  | 10.9    |
| 35409    | 40 | 42                   | 1 1/2  | 1 3/4  | 11.5    |
| 35410    | 50 | 54                   | 2      | 2 3/8  | 12.9    |