

compact Pin Busbar, 10mm² connection: 1p/N AFDD 5SM6 +
compact device 1-pole + auxiliary switch 0,5-pole touch protected
1000mm cuttable



Versie

productmerksnaam SENTRON

Algemene technische gegevens

aantal fasen 1

Elektriciteit

continustroom / nominale waarde 63 A

Hoofd-circuit

bedrijfsspanning / nominale waarde / maximaal 230 V

Geschiktheid

geschiktheid voor samenwerking

- apparaten met hulpschakelaar Ja
- apparaten met nulgeleider Ja

Product Details

producteigenschap / elektrisch geïsoleerd Ja

Aantal

aantal apparaten / geschikt voor aanbouw 24

Aansluitingen

uitvoering van de elektrische aansluiting	Stift
---	-------

Mechanical Design

verdelingsmaat	2,5 mm
hoogte	13 mm
lengte	1 035,9 mm
nettogewicht	392 g

Certificaten

Declaration of Conformity



EG-Konf.

Verdere informatie

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/nl/nl/Catalog/product?mlfb=5ST3780-0>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/nl/ps/5ST3780-0>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)



http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=5ST3780-0

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

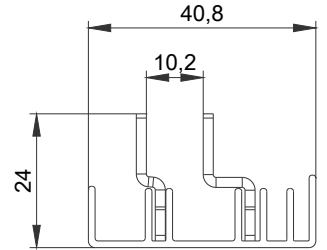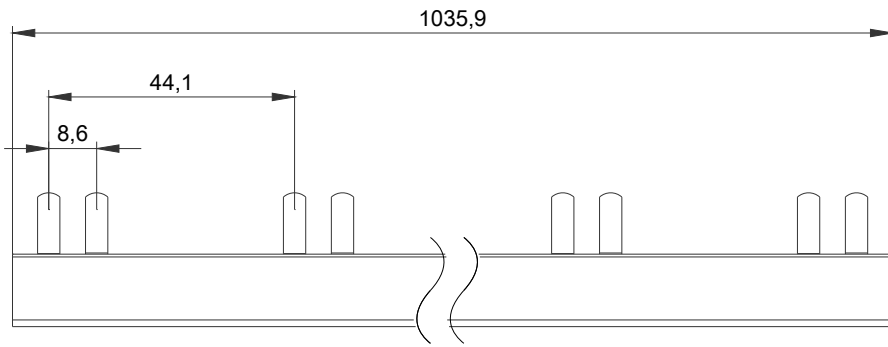

5ST3780-0

