


MicroCamera G3

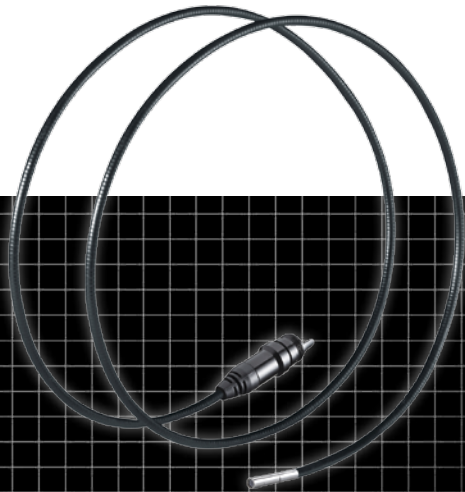

1,5 m
DOF 1...6 cm



Universal micro camera with very small camera head and flexible cable

Rev 0617



- **Problem locating:** the camera indicates what is behind or in objects, walls circuits or cables etc. even under worst light conditions, due to the LED-lighting.
- **Ideal for difficult accessibility areas** due to the very small measuring head (ø 6 mm)
- **Waterproof camera head and cable**
- Powerful object lighting thanks to **4 high-performance LEDs**

TECHNICAL DATA

CAMERA HEAD / CABLE ø 6 mm, IP 68 (immersion depth 1,5 m, 60 min.)
CAMERA FOCUS F1 cm - F6 cm
CAMERA RESOLUTION 640 x 480 pixels
CABLE DIAMETER 5 mm
LENGTH OF FLEX CABLE 1,5 m
OPERATING TEMPERATURE 0°C... 45°C
STORAGE TEMPERATURE -10°C ... 60°C
WEIGHT 150 g
DIMENSIONS (W x H x D) 1500 mm x 17 mm x 17 mm

Only for VideoFlex G3.



Camera head (ø 6 mm) with LED-Lighting



MicroCamera G3

Packing dimension (W x H x D)
190 x 10 x 180 mm

ARTICLE	ARTICLE NO.	EAN CODE	PU
MicroCamera G3	082.221A	4 021563 694938	2

CAMERA 640 x 480 pixel **LED LIGHT** **IP 68**