


Machine & Inspection Light

Adj arm loading bay luminaire 55w 12/24v

The Loading Bay is a powerful luminaire, ideal for those areas that require extra illumination. The universal base can be mounted vertically or horizontally

Features:

- High quality friction arm joints, move easily, yet retain position, tested to over 30,000 movements
- Vibration resistant mountings, arms and lampholders for demanding operating conditions
- Versatile and flexible positioning, relative to subject, based on variety of arm length combinations
- Shade is design maximises the light output from lamp
- Moulded handle for ease of adjustment
- Cable is totally enclosed within the arms and base
- Metal parts are coated in tough chip resistant epoxy polyester powder paint
- Switch is located on rear of head for ease of use
- Head is moulded from strong shock resistant thermoplastic material which acts as an electrical insulator

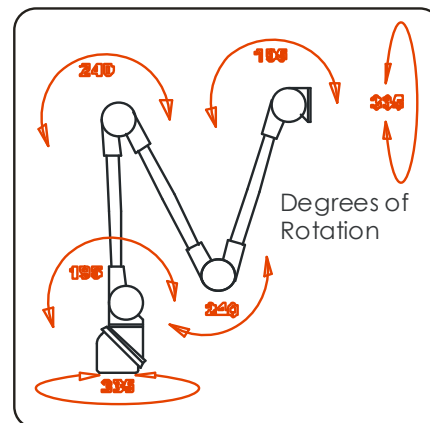

Primary Voltage:	12v & 24v ensure lamp is of suitable voltage
Lamp Type:	Halogen
Max Wattage:	12v 55w or 24v 70w
Lamp Base:	P14.5s
Switch Fitted:	Yes on head
IP Rating:	IP 44
Base Type:	Universal Base – can be horizontal or vertical mounted
Arms:	3 400mm + 400mm + 400mm
Head:	Moulded plastic
Shield Fitted:	Yes (clear polycarbonate)
Visor:	not applicable
Trailing Cable:	Not fitted
Manufacturing Standard:	BS EN 60598
RHOS Compliant:	Not applicable
WEE Compliant:	Not applicable
Head Colour:	Black
Arms Finish & Colour:	Powder coated Gunmetal Grey

Accessories:

Lamps



H3 Halogen Lamp
12v 55 watts



H3 Halogen Lamp
24v 70 wat

Clamps & cable assemblies

Clamp 744-003



Transformers

The MT 60VA transformer series is designed for use with 600-723, 743-943, 743-937, Task 24-12v & Task 24-24v along with Load bay luminaire 743-993



Order Code	Primary Voltage	Secondary Voltage
MT5s	240v	12/25v ac
MT10s	240v	25/50v ac
MT15s	415v	12/24v ac
MT20s	415v	25/50v ac
MT25s	415v	110v ac



Universal Base Mounting

