


FEATURES

- **Nylon Material:** Provides durability and resistance to wear and tear.
- **Length of 385 mm:** Suitable for bundling larger cable groups.
- **Maximum Bundle Diameter of 110 mm:** Accommodates a wide range of cable sizes.
- **Tensile Strength of 22 kg:** Ensures secure fastening and reliability.
- **Maximum Operating Temperature of 150 °C:** Suitable for high-temperature environments.
- **UL 94 V-2 Fire Behaviour:** Offers flame retardancy for added safety.
- **Width of 4.8 mm:** Balances flexibility and strength for various applications.

RS PRO Nylon Cable Tie, 385 mm Length

RS Stock No: 656-014

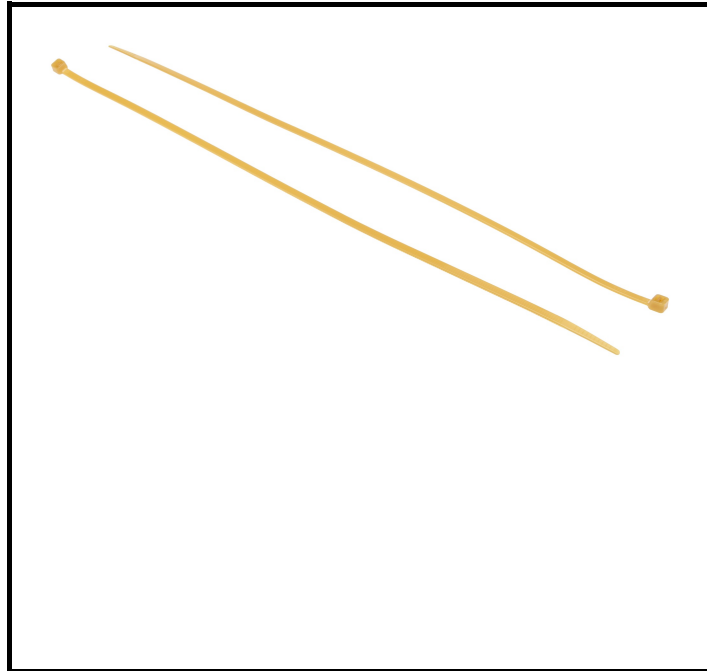

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

RS PRO offers a reliable and durable nylon cable tie designed for securing and organising cables and wires. With a length of 385 mm, this non-releasable cable tie is ideal for applications requiring a strong and permanent bundling solution. It is particularly beneficial in environments where high tensile strength and temperature resistance are crucial.

General Specifications

Colour	Light Brown
Product Type	Cable Tie
Sub Type	Non-Releasable
Tensile Strength	22 kg

Protection Category

Fire Behaviour	UL 94 V-2
UV Resistant	No

Mechanical Specifications

Length	385 mm
Material	Nylon
Maximum Bundle Diameter	110 mm
Width	4.8 mm

Operation Environment Specifications

Maximum Operating Temperature	150 °C
-------------------------------	--------

Approvals

Standards/Approvals	RoHS, UL94V-2
---------------------	---------------

