



+FLEX 208

IP20 Flexible LED Tape

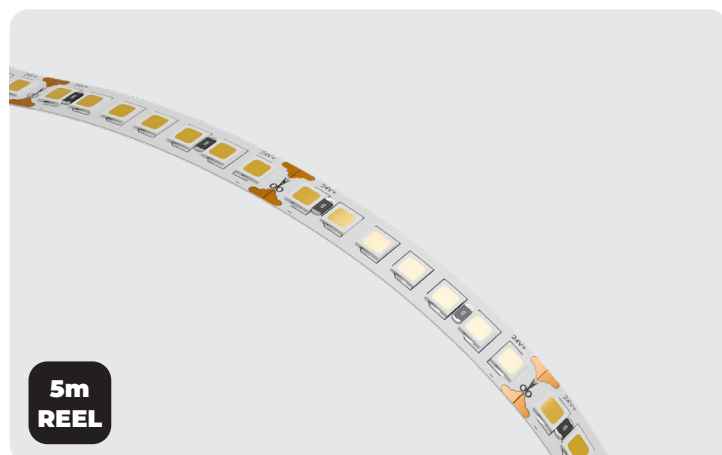


Product Features

 - Available in four different colour temperatures
- Industrial grade adhesive backing tape
- Bespoke design and cutting service available
- Operating temperature -20°C ~ +45°C
- Humidity 40% - 70% RH
- High efficacy
- 3 years warranty



Specifications

Stock Code	0995-515	1020-290	0323-778	1249-959
Part Code	B7-2-208-20	C0-2-208-20	D0-2-208-20	F0-2-208-20
Voltage	24VDC	24VDC	24VDC	24VDC
Power Consumption	12.7W/m	12.7W/m	12.7W/m	12.7W/m
Lumen Output	1890lm/m	1940lm/m	1995lm/m	1995lm/m
Efficacy	149lm/W	153lm/W	157lm/W	157lm/W
Colour Temperature	2700K	3000K	4000K	6000K
LED/metre	208	208	208	208
LED Pitch	4.81mm	4.81mm	4.81mm	4.81mm
Cut Points	38.45mm	38.45mm	38.45mm	38.45mm
CRI (Ra)	>80	>80	>80	>80
IP Rating	IP20	IP20	IP20	IP20
Dimensions	5000 x 8 x 1.2mm	5000 x 8 x 1.2mm	5000 x 8 x 1.2mm	5000 x 8 x 1.2mm

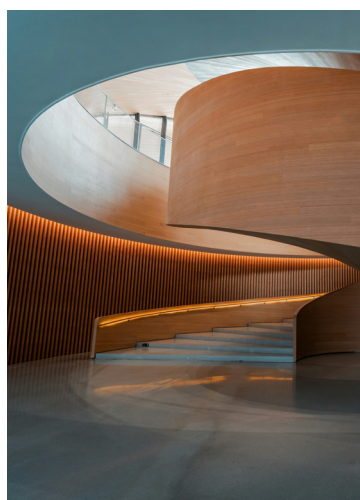

2700K



3000K



4000K




6000K




+FLEX 208

IP65 Flexible LED Tape

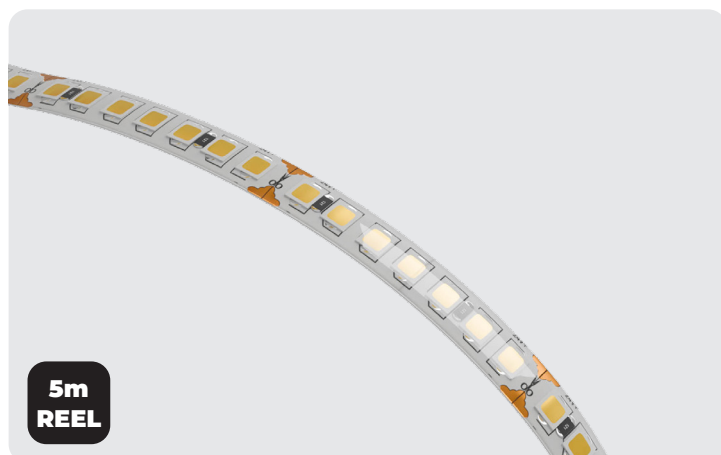

Product Features

 - Available in three different colour temperatures
- Industrial grade adhesive backing tape
- Bespoke design and cutting service available
- Operating temperature -20°C ~ +45°C
- Humidity 40% - 70% RH
- High efficacy
- 3 years warranty



Specifications

Stock Code	0991-251 	1053-421 	1592-974 
Part Code	C0-2-208-65	D0-2-208-65	F0-2-208-65
Voltage	24VDC	24VDC	24VDC
Power Consumption	12.7W/m	12.7W/m	12.7W/m
Lumen Output	1777lm/m	1777lm/m	1815lm/m
Efficacy	140lm/W	140lm/W	143lm/W
Colour Temperature	3000K	4000K	6000K
LED/metre	208	208	208
LED Pitch	4.81mm	4.81mm	4.81mm
Cut Points	38.45mm	38.45mm	38.45mm
CRI (Ra)	>80	>80	>80
IP Rating	IP65	IP65	IP65
Dimensions	5000 x 8 x 2.2mm	5000 x 8 x 2.2mm	5000 x 8 x 2.2mm



3000K



4000K



6000K




+FLEX 208

IP20 & IP65 Flexible LED Tape



Compatibility*

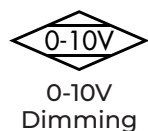

Suggested Drivers

Non-Dimmable

Up to 1m

Power supplied from ONE end
PCV2420

Up to 3m

Power supplied from ONE end
PCV2450-REV-A

Up to 5m

Power supplied from ONE end
PCV2475-REV-B

Up to 10m

Power supplied from MIDDLE
PCV24151

Mains Dimming

Up to 1m

Power supplied from ONE end
UVC2425TD-REV-A

Up to 3m

Power supplied from ONE end
UVC2450TD-REV-A

Up to 5m


Power supplied from ONE end
UVC24100TD-REV-A

Up to 10m


Power supplied from MIDDLE
UVC24200ETD-REV-A

Mechanical Diagram

IP20

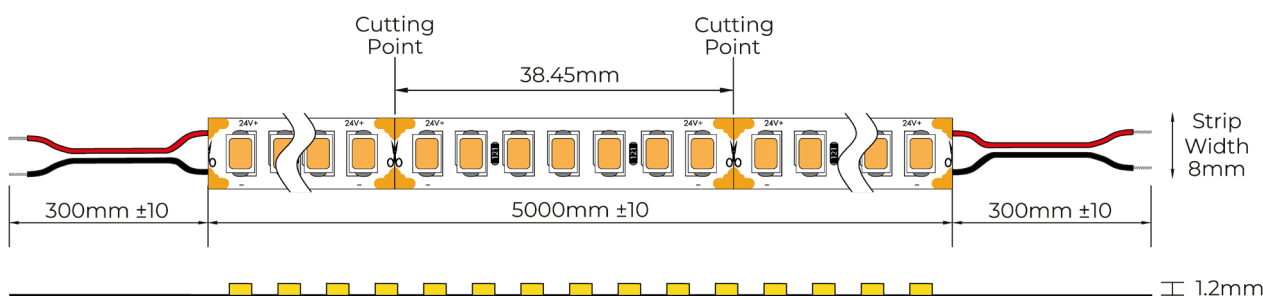

IP65

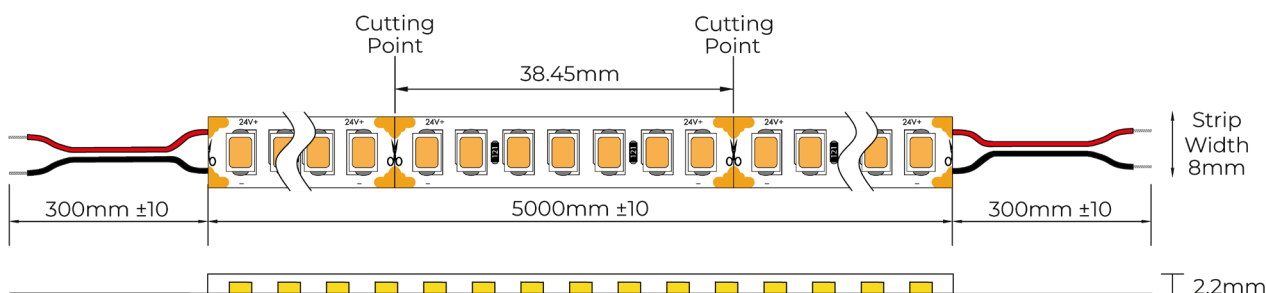

* Product compatibility with other brands is shown for informational purposes only. All third-party company names and logos are trademarks of their respective owners and do not constitute an endorsement or partnership with our company.