


 


Grab containers

(see page 68, see page 69)

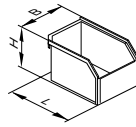

					Static load limit			
					Container mount	Suspension profile		
					(kg)	(kg)		
					ESD No.			
					(mm) (cm ³)			
					B x H x L			
GB-Axxxx cover Material: PC plastic Min./max. ambient temperature: -40 °C/115 °C Resistant to diluted acidic and caustic materials, alcohol (except for methanol), grease, oils, glycol, water ESD version Material: ABS-CF Min./max. ambient temperature: -40 °C/70 °C Resistant to diluted acidic and caustic materials, alcohol (except for methanol), grease, oils, glycol, water		GB-A0805	77x13x173	–	3 842 344 756	–	–	
					⚠	3 842 346 286	–	–
		GB-A1205	117x13x173	–	3 842 344 757	–	–	
					⚠	3 842 346 287	–	–
		GB-A1210	117x32x173	–	3 842 344 758	–	–	
					⚠	3 842 346 288	–	–
		GB-A1710	167x32x245	–	3 842 344 759	–	–	
					⚠	3 842 346 289	–	–
						3 842 557 478 ¹	–	–
GB-Sxx grab tray GB-xxxx grab container G-Zxx grab ledge Material: ABS plastic Min./max. ambient temperature: -40 °C/70 °C Resistant to mildly acidic and caustic materials, alcohols, greases, oils, water ESD version Material: ABS-CF Min./max. ambient temperature: -40 °C/70 °C Resistant to diluted acidic and caustic materials, alcohol (except for methanol), grease, oils, glycol, water		GB-S08	82x50x86	150	3 842 344 764	11	17	
					⚠	3 842 346 294	6	10
		GB-S12	123x50x86	240	3 842 344 765	11	19	
					⚠	3 842 346 295	6	11
		GB-S17	173x50x86	360	3 842 344 766	11	21	
					⚠	3 842 346 296	6	12
		GB-0805	82x50x173	370	3 842 344 750	10	26	
					⚠	3 842 346 280	6	15
		GB-1205	123x50x173	600	3 842 344 751	10	26	
					⚠	3 842 346 281	6	15
		GB-1210	123x100x173	1370	3 842 344 752	10	26	
					⚠	3 842 346 282	6	15
GB-1710	173x100x245	3050	3 842 344 753	13	30			
			⚠	3 842 346 283	8	18		
				3 842 555 685 ¹	8	18		
	GB-Z08	90x54x277	690	3 842 344 760	10	30		
				⚠	3 842 346 290	6	18	
	GB-Z12	131x54x277	1050	3 842 344 761	6	23		
				⚠	3 842 346 291	3	13	

¹ Red version