
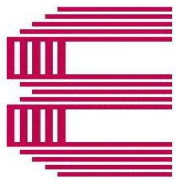



Product information ASBSV 8/LED 5 11138

Name	
ASBSV 8/LED 5	
	
	Pluggable actuator/sensor distribution box, 8 port version, with LED operation and function indicators, combined FIXCOM/M12 socket, 5-pole, 2 signals per socket, earth connection, M23 connection for the control cable.
Delivery informations	
Availability	available
Product description	
Type	ASBSV 8/LED 5
Order No.	11138
Description	Pluggable actuator/sensor distribution box, 8 port version, with LED operation and function indicators, combined FIXCOM/M12 socket, 5-pole, 2 signals per socket, earth connection, M23 connection for the control cable.
Number of contacts	5 (M12)
Version	8 ports
Color of housing	orange
Product characteristics	Vibration resistance, Oil resistance
Classification	
Belden brand	Lumberg-Automation
Mechanical data	
Thread	M12
LED display present	✔
Environmental conditions	
Environmental temperature	-15 °C ... 80 °C
Degree of protection (IP), mounted	IP67
Pollution degree	3
Materials	
Housing material / Molded body	TPU, self-extinguishing
Contact bearer material	PA-GF, self-extinguishing
Contact material	CuZn
Contact material - Surface refinement	pre-nickel and 0.8 microns gold-plated
Knurled screw / nut material	CuZn, nickel-plated
Sealing material	FKM
Electrical data	
Contact resistance	≤ 5 mΩ
Rated current In	4 A per socket / 10 A max. at 40°C
Nominal voltage	10 - 30 V DC
Rated voltage	32 V
Insulation resistance	> 1 GΩ
Approvals	
Approvals	cURus
Scope of delivery and accessories	
Scope of delivery	ZVK: 2 dust covers for unused sockets ZBS: 10 attachable labels

The information published has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price related/commercial respect.



Picture
Drawing

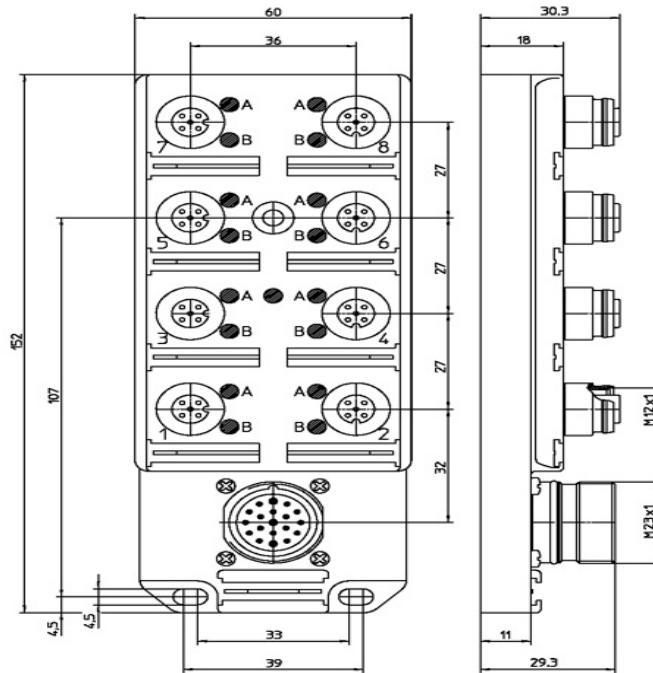

The information published has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price related/commercial respect.